




Fibre optic through-beam sensor

FE-00-P-A-R3/0,18M +10MM

Article no longer available - archive entry

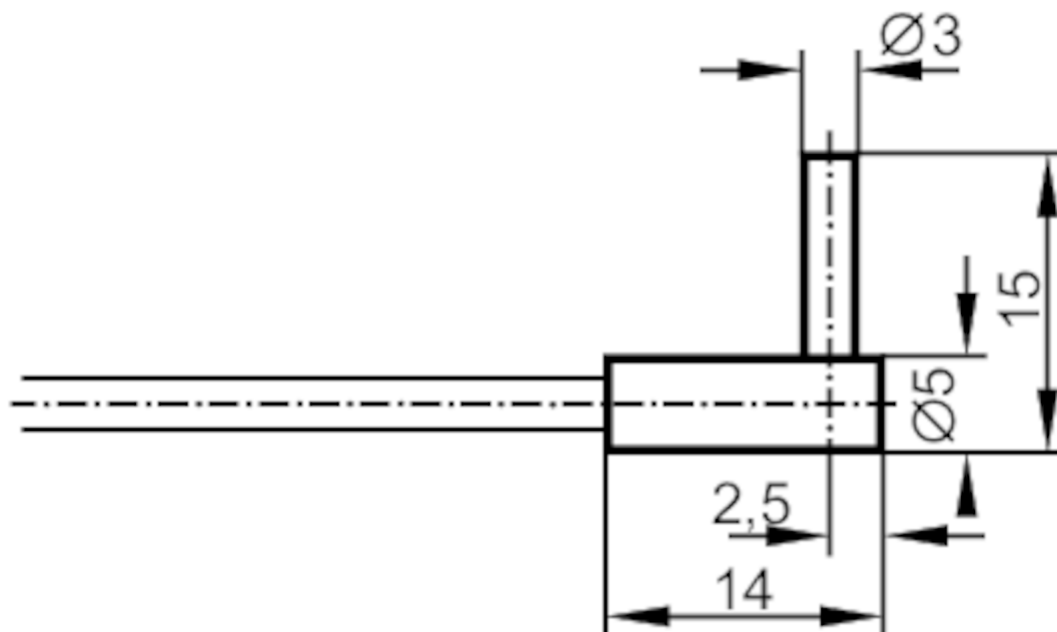

Application

Function principle

Through-beam sensor

Detection zone

Range with fibre-optic
amplifier type

OKF; OUF

OKF

Range of fibre optics

[mm]

40

OUF

Range of fibre optics

[mm]

40

Operating conditions

Ambient temperature

[°C]

-20...80

Mechanical data

Version of sensing head

angled

Sensing head diameter

[mm]

3

Sensing head length

[mm]

10

Total length

[mm]

180; (+10 mm)

Min. bending radius

[mm]

10

Materials

Adapter: PPE

Fibre material

glass

E20450



Fibre optic through-beam sensor

FE-00-P-A-R3/0,18M +10MM

Fibre head material	aluminium
Fibre sheath material	PVC
Remarks	
Pack quantity	1 pcs.