


Fibre optic diffuse reflection sensor

FT-00-M-V-E3 1m

Article no longer available - archive entry

Alternative articles: E20526

When selecting an alternative article and accessories please note that technical data may differ!

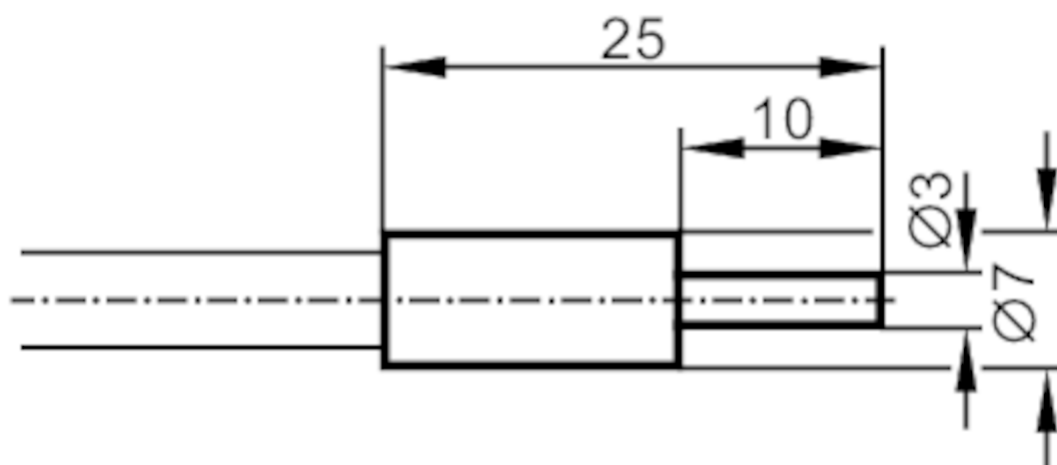

Application

Function principle

Diffuse reflection sensor

Detection zone

Range with fibre optic amplifier type

OKF; OUF

OKF

Range fibre optics

[mm]

40

OUF

Range fibre optics

[mm]

40

Operating conditions

Ambient temperature

[°C]

-20...150

Mechanical data

Version of sensing head

straight

Sensing head diameter

[mm]

3

Sensing head length

[mm]

10

Total length

[mm]

1000

E20501



Fibre optic diffuse reflection sensor

FT-00-M-V-E3 1m

Min. bending radius	[mm]	20
Fibre material		glass
Fibre head material		stainless steel (1.4305 / 303)
Fibre sheath material		metal silicone
Remarks		
Pack quantity		1 pcs.