


Fibre optic diffuse reflection sensor

FT-00-A-A-M6

Article no longer available - archive entry

Alternative articles: E20055

When selecting an alternative article and accessories please note that technical data may differ!

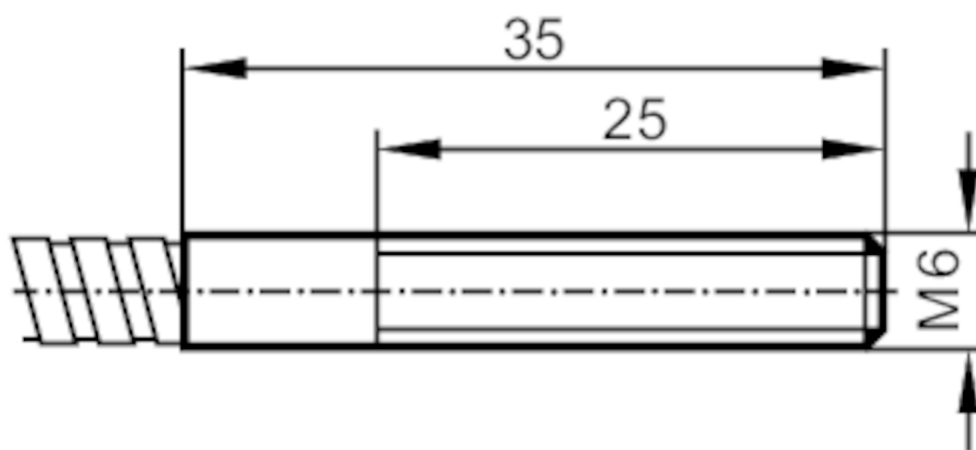

Application

Function principle

Diffuse reflection sensor

Detection zone

Range with fibre optic amplifier type

OKF; OUF

OKF

Range fibre optics

[mm]

20

OUF

Range fibre optics

[mm]

20

Operating conditions

Ambient temperature

[°C]

-20...80

Mechanical data

Version of sensing head

straight

Sensing head thread

M6

Sensing head length

[mm]

35

Total length

[mm]

600

E20503



Fibre optic diffuse reflection sensor

FT-00-A-A-M6

Min. bending radius	[mm]	20
Materials		Adapter: ABS
Fibre material		acrylic
Fibre head material		aluminium
Fibre sheath material		aluminium
Remarks		
Pack quantity		1 pcs.