


E2M203



Adapter cables for cameras with video output

CONNECTION CABLE M16 5M

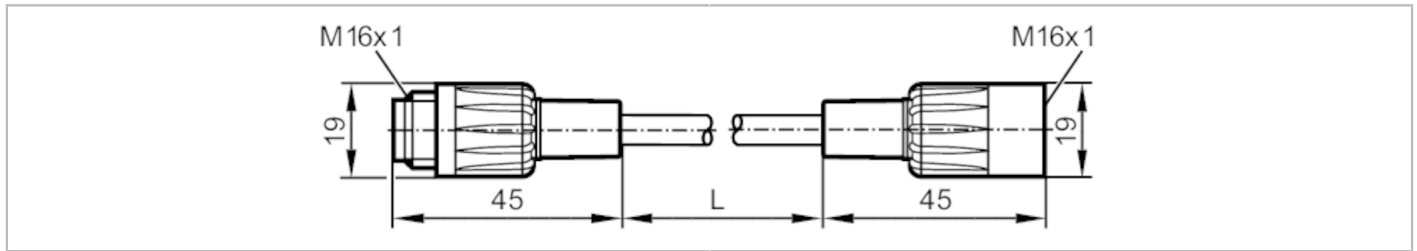

| Application | |
|-----------------------------|--|
| Special feature | Free from silicone; Gold-plated contacts |
| Design | camera with video output O2M20x |
| Free from silicone | yes |
| Electrical data | |
| Operating voltage [V] | < 60 DC |
| Protection class | II |
| Max. current load total [A] | 4 |
| Operating conditions | |
| Ambient temperature [°C] | -45...85 |
| Protection | IP 67 |
| Mechanical data | |
| Weight [g] | 307.5 |
| Materials | housing: PVC; Sealing: EPDM |
| Material nut | PVC |
| Remarks | |
| Pack quantity | 1 pcs. |

Electrical connection - plug

Connector: 1 x M16, straight; coding: A; Locking: PVC; Contacts: gold-plated; Tightening torque: 0.6...1.5 Nm



E2M203




Adapter cables for cameras with video output

CONNECTION CABLE M16 5M

Electrical connection

Cable: 5 m, PVC, black, \varnothing 6 mm; 3 x 0.34 mm² / AWG 22 + 1 x 0.11 mm² / AWG 26

Connection

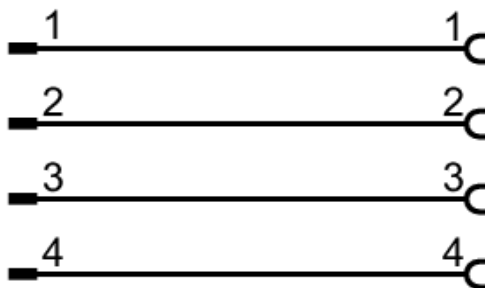

Electrical connection - socket

Connector: 1 x M16, straight; coding: A; Locking: PVC; Contacts: gold-plated; Tightening torque: 0.6...1.5 Nm

