




## Thermowell for temperature sensors

THERMOWELL, D3/DIN10/15/20 CLAMP/EL=38

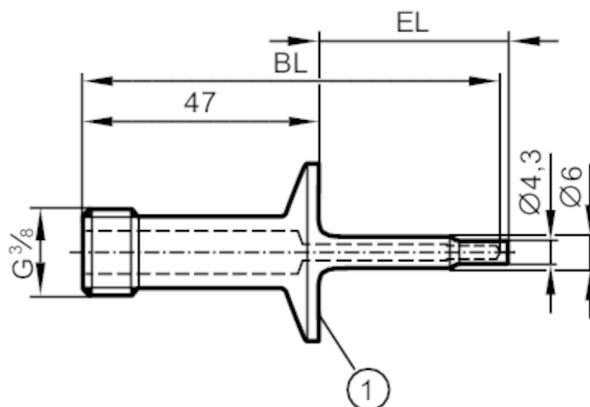

EC 1935/2004 FDA

### Application

|                       |                                    |
|-----------------------|------------------------------------|
| Design                | for temperature sensors EL = 83 mm |
| Pressure rating [bar] | 25                                 |

### Mechanical data

|                                                   |                                                     |
|---------------------------------------------------|-----------------------------------------------------|
| Weight [g]                                        | 70                                                  |
| Materials                                         | stainless steel (316L/1.4435)                       |
| Sensor connection                                 | G 3/8 internal thread Ø 3 mm                        |
| Process connection                                | Clamp DN10...DN20 (1/2...3/4") DIN 32676 (ISO 2852) |
| Surface characteristics Ra/Rz of the wetted parts | < 0.4 / -                                           |
| Installation length EL [mm]                       | 38                                                  |
| Bore length BL [mm]                               | 83                                                  |

### Remarks

|               |        |
|---------------|--------|
| Pack quantity | 1 pcs. |
|---------------|--------|