



## Connecting cable with socket

ADOGG030--S0010A03

Article no longer available - archive entry

# No scale drawing available

### Application

Special feature	Halogen-free
-----------------	--------------

### Electrical data

Operating voltage [V]	< 60 AC / < 75 DC
Protection class	III

### Operating conditions

Ambient temperature [°C]	-25...90
Protection	IP 65

### Mechanical data

Dimensions [mm]	8 x 8 x 31
Materials	TPU
Moulded-body material	TPU

### Remarks

 
Pack quantity	1 pcs.
---------------	--------

### Electrical connection

Cable: 10 m, PUR / PVC, Halogen-free, orange, Ø 5 mm; 3 x 0.34 mm<sup>2</sup> (42 x Ø 0.1 mm )

### Electrical connection - socket

Connector: 1 x M8, straight; Moulded body: TPU




# E10623



## Connecting cable with socket

ADOGG030--S0010A03

### Connection

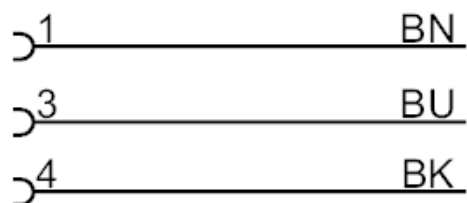

Core colours :

BK = black  
BN = brown  
BU = blue