

E11019




Splitter box

ZDO6H05DMSS0005H15

Article no longer available - archive entry

Alternative articles: EBC020

When selecting an alternative article and accessories please note that technical data may differ!

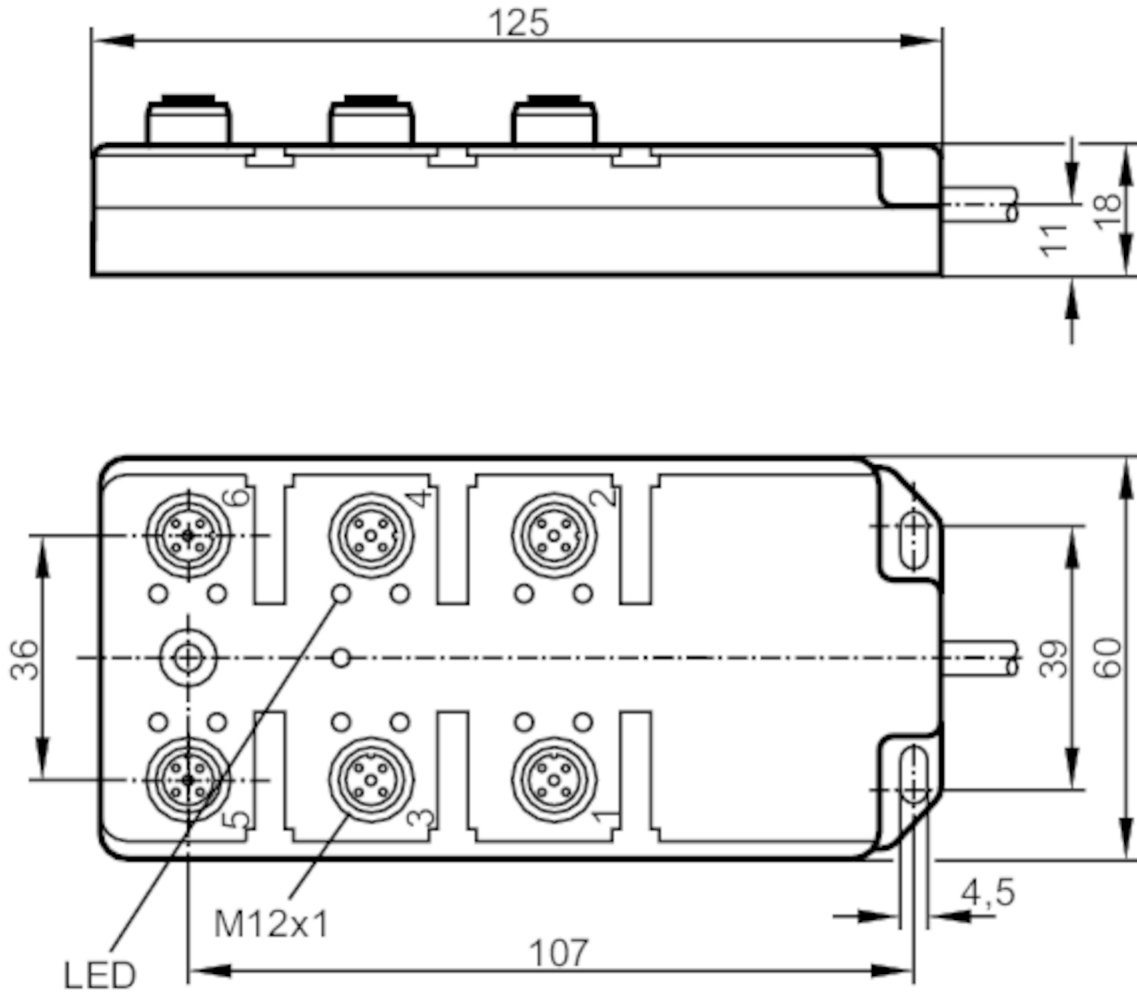

Application	
Special feature	Free from silicone; Halogen-free; Gold-plated contacts
Free from silicone	yes
Electrical data	
Operating voltage [V]	10...30 DC
Protection class	II
Max. current load per module/slot [A]	4
Max. current load total [A]	12
Outputs	
Electrical design	PNP

E11019



Splitter box

ZDO6H05DMSS0005H15

Operating conditions		
Ambient temperature	[°C]	-15...80
Protection		IP 67
Mechanical data		
Materials		TPU
Moulded-body material		TPU
Number of ports splitter box		6
Connector type		M12
Displays / operating elements		
Display	switching status	12 x LED, yellow
	operation	1 x LED, green
Remarks		
Pack quantity		1 pcs.
Electrical connection		
Cable: 5 m, PUR, Halogen-free, black, Ø 10.4 mm; 12 x 0.5 mm ² (63 x Ø 0.1 mm) + 3 x 1.0 mm ² (127 x Ø 0.1 mm)		
Electrical connection - slot		
Connector: 6 x M12; Moulded body: TPU; Contacts: gold-plated; Tightening torque: 0.5 Nm		


E11019



Splitter box

ZDO6H05DMSS0005H15

Connection

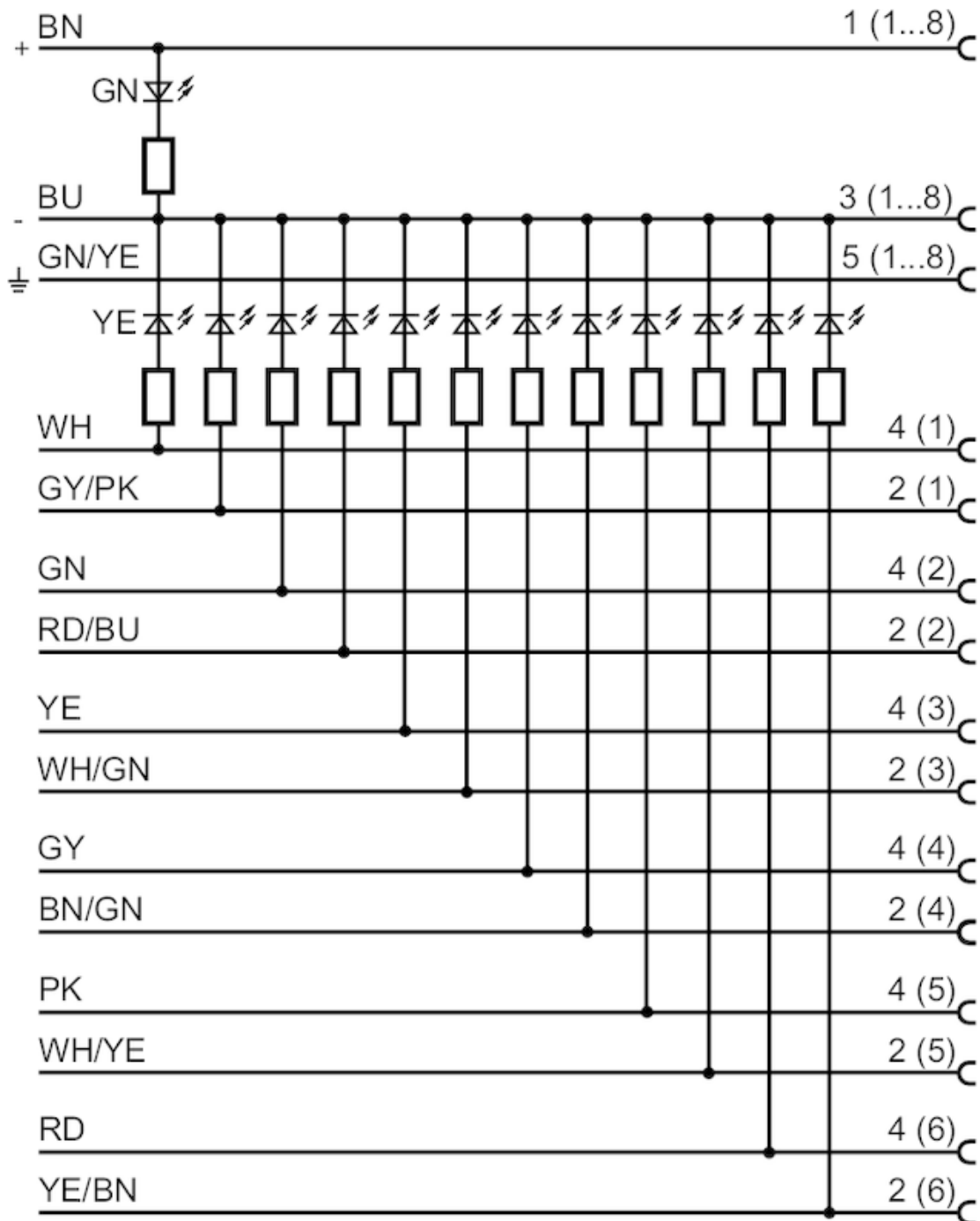

Core colours :

BN = brown

BU = blue

GN = green

E11019

Splitter box

ZDO6H05DMSS0005H15

