


E12556



Connection cable

VDOGS040PLS0001H04DOGS040PLS

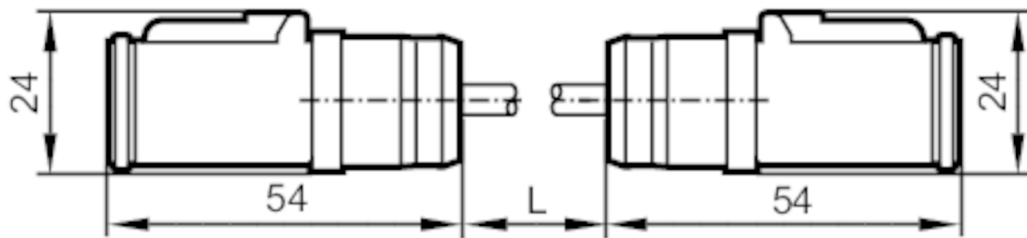

Application

Special feature	Free from silicone; Halogen-free
Free from silicone	yes

Electrical data

Operating voltage [V]	12...24 DC
Protection class	III
Max. current load total [A]	4

Operating conditions

Ambient temperature [°C]	-40...85
Ambient temperature (moving) [°C]	-30...70
Protection	IP 67; (mating connector plugged in)

Mechanical data

Weight [g]	119
Moulded-body material	PA

Remarks

Pack quantity	1 pcs.
---------------	--------

Electrical connection

Cable: 1 m, PUR, Halogen-free, lilac, Ø 6.4 mm; twisted; 2 x 0.50 mm² (28 x 0.15 mm) + 2 x 1 mm² (52 x 0.15 mm)

Electrical connection - socket


Connector: 2 x DEUTSCH connector, straight; Moulded body: PA; Contacts: nickel-plated

E12556



Connection cable

VDOGS040PLS0001H04DOGS040PLS

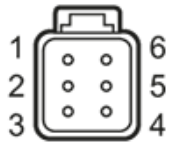

Connection

