


E10532



Connecting cable with socket

ADOAH040MSS07,5E03

Article no longer available - archive entry

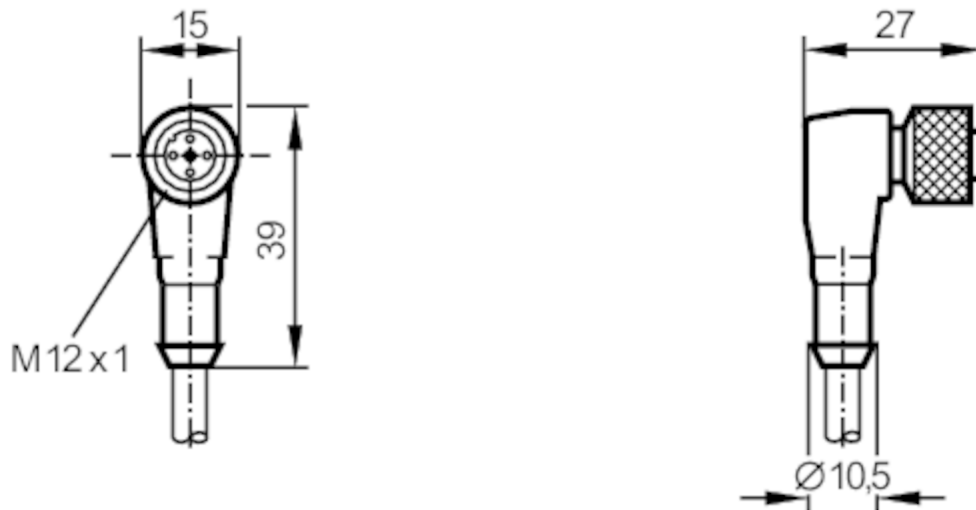

Electrical data

Operating voltage [V] < 250 AC / < 300 DC

Operating conditions

Ambient temperature [°C] -25...70

Protection IP 67

Mechanical data

Dimensions [mm] 27 x 15 x 39

Materials TPU

Material nut brass, nickel-plated

Remarks

 
Pack quantity 1 pcs.

Electrical connection

Cable: 7.5 m, PVC, orange, Ø 5 mm; 3 x 0.34 mm² (42 x Ø 0.1 mm)

Electrical connection - socket

Connector: 1 x M12, angled; Moulded body: TPU; Locking: brass, nickel-plated




E10532



Connecting cable with socket

ADOAH040MSS07,5E03

Connection

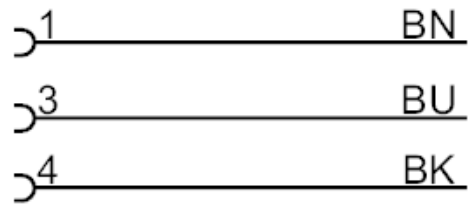

Core colours :

BN = brown
BK = black
BU = blue

Article no longer available - archive entry