


Fibre optic diffuse reflection sensor

FT-00-P-V-E1/0,4M

Article no longer available - archive entry

Alternative articles: E20077

When selecting an alternative article and accessories please note that technical data may differ!

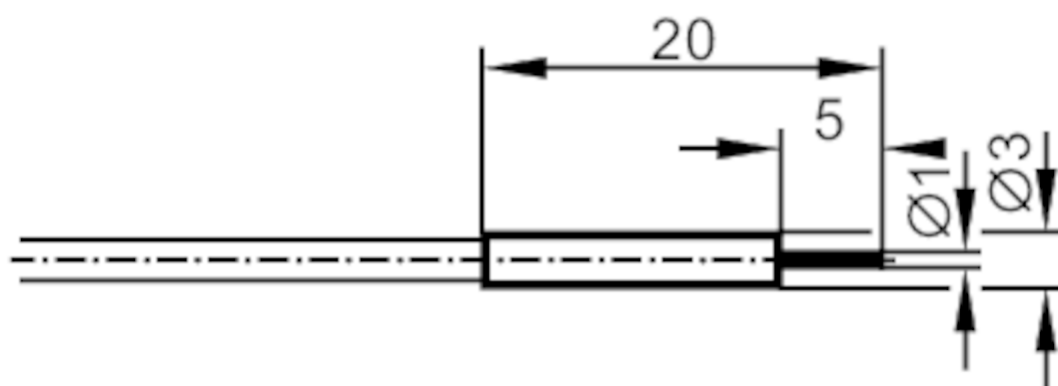

Application

Function principle

Diffuse reflection sensor

Detection zone

Range with fibre optic
amplifier type

OKF; OUF

OKF

Range fibre optics

[mm]

8

OUF

Range fibre optics

[mm]

8

Operating conditions

Ambient temperature

[°C]

-20...80

Mechanical data

Version of sensing head

straight

Sensing head diameter

[mm]

1

Sensing head length

[mm]

5

Total length

[mm]

400

E20373



Fibre optic diffuse reflection sensor

FT-00-P-V-E1/0,4M

Min. bending radius	[mm]	10
Materials	Adapter: PPE	
Fibre material	glass	
Fibre head material	stainless steel (303/1.4305)	
Fibre sheath material	PVC	
Accessories		
Items supplied	Mounting clamp:, E20107	
Remarks		
Pack quantity	1 pcs.	