

AC2210




AS-Interface control cabinet module

Modul aktiv, 4E 200mA/4AT PNP

Article no longer available - archive entry

Alternative articles: AC2257

When selecting an alternative article and accessories please note that technical data may differ!

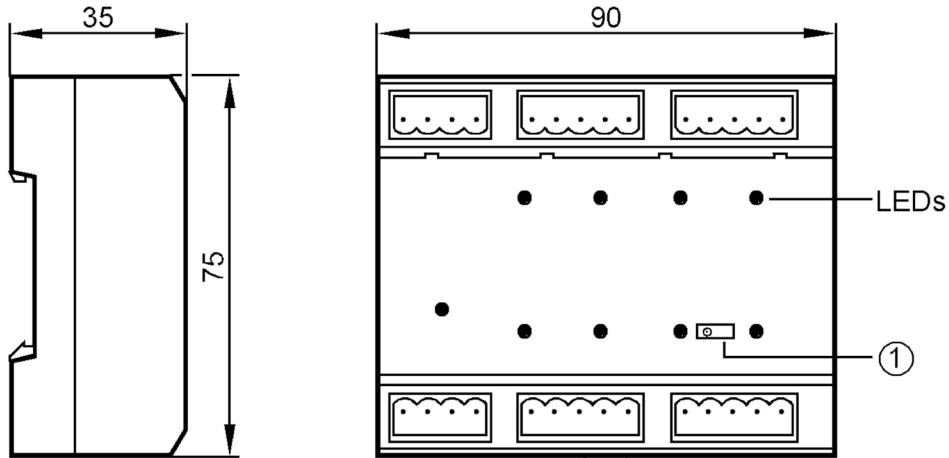

1 addressing socket



Electrical data

Operating voltage	[V]	26.5...31.6 DC
Current consumption	[mA]	< 235
Max. current load total	[A]	6
Integrated watchdog		yes

Inputs / outputs

Number of inputs and outputs Number of digital inputs: 4; Number of digital outputs: 4

Inputs

Number of digital inputs	4; (bidirectional)
Input circuit of digital inputs	PNP
Sensor supply of the inputs	AS-i
Power supply	[V] 20...30
Max. total current rating of inputs	[mA] 200
Input current High	[mA] > 5
Input current Low	[mA] < 1.5
Switching level high	[V] > 10
Digital inputs protected against short circuits	yes

AC2210



AS-Interface control cabinet module

Modul aktiv, 4E 200mA/4AT PNP

Outputs		
Electrical design		AS-i
Number of digital outputs		4
Circuit		PNP
Voltage range DC [V]		10...30; (to PELV)
Max. current load per output [mA]		2000
Short-circuit proof		yes
Electrically separated		yes
Operating conditions		
Ambient temperature [°C]		-25...80
Protection		IP 20
Tests / approvals		
EMC		EN 50295
AS-i classification		
AS-i profile		S-7.0
AS-i I/O configuration [hex]		7
AS-i ID code [hex]		0
AS-i certificate		05001
Mechanical data		
Type of mounting		mounting on DIN rail
Materials		PA; PVC
Displays / operating elements		
Display	switching status	LED, yellow
	operation	LED, green
Remarks		
Pack quantity		1 pcs.
Electrical connection		
Connection		

