


AS-Interface repeater

SmartLine25 AS-i Repeater

Article no longer available - archive entry

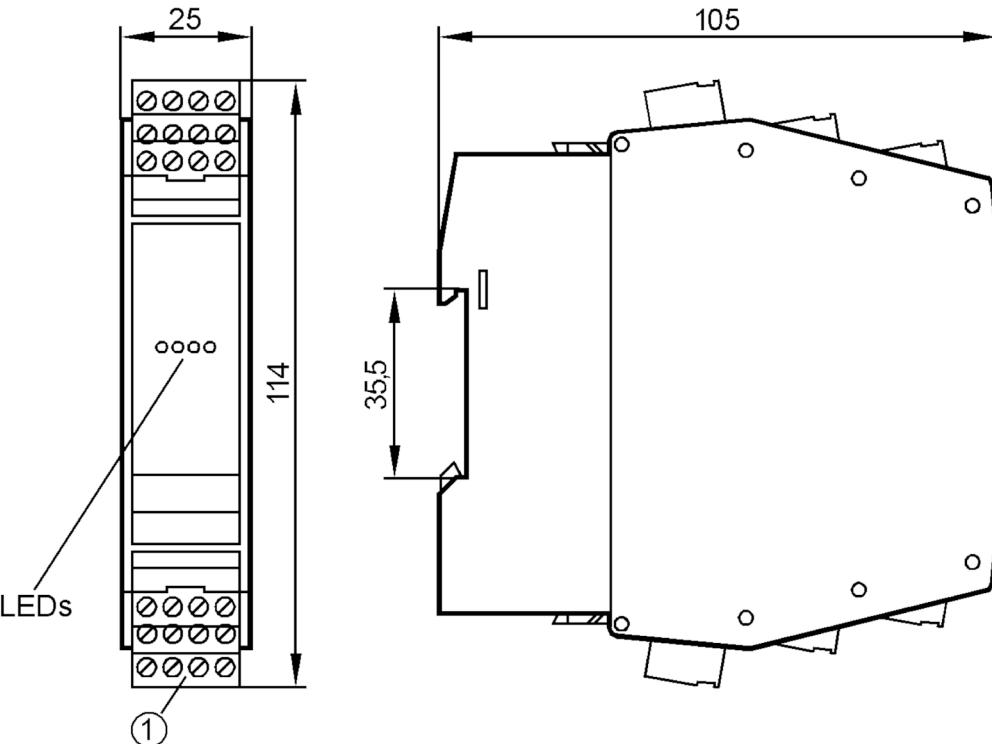

1 COMBICON connector with screw terminals optional

**Application**

Application	extension of the AS-i network by another 100 m
-------------	--

Electrical data

Nominal voltage DC	[V]	26.5...31.6
--------------------	-----	-------------

Max. current consumption from AS-i	[mA]	2
------------------------------------	------	---

Undervoltage monitoring	no
-------------------------	----

Outputs

Electrical design	AS-i
-------------------	------

Electrically separated	yes
------------------------	-----

Operating conditions

Ambient temperature	[°C]	0...55
---------------------	------	--------

Protection	IP 20
------------	-------

Tests / approvals

EMC	EN 50295
-----	----------

Mechanical data

Housing	mounting on DIN rail
---------	----------------------

Materials	PA 6.6
-----------	--------

Displays / operating elements

Display	operation	2 x LED, green
	short circuit	2 x LED, red

AC2215



AS-Interface repeater

SmartLine25 AS-i Repeater

Remarks

Remarks

The AS-i extender takes no slave address.

The total number of slaves per master string remains unchanged.

 
No parameter setting necessary.

Pack quantity

1 pcs.

Electrical connection

Connection



A1+	AS-i + string 1
A1-	AS-i - string 1
A2+	AS-i + string 2
A2-	AS-i - string 2