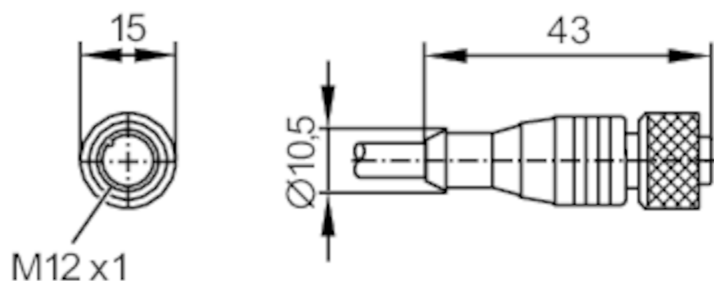


Connecting cable with socket

ADOGH040MSS0005G04

Article no longer available - archive entry

**Application**

Special feature

Screened cable

Electrical data

Operating voltage

[V]

< 50 AC / < 60 DC

Protection class

III

Operating conditions

Ambient temperature

[°C]

-25...70

Protection

IP 67

Mechanical data

Dimensions

[mm]

15 x 15 x 43

Materials

TPU

Moulded-body material

TPU

Material nut

brass, nickel-plated

Remarks

Pack quantity

1 pcs.

E10432



Connecting cable with socket


ADOGH040MSS0005G04

Electrical connection


Cable: 5 m, PVC, orange, Ø 5 mm, shielded; 4 x 0.25 mm² (32 x Ø 0.1 mm)

Electrical connection - socket

Connector: 1 x M12, straight; coding: A; Moulded body: TPU; Locking: brass, nickel-plated; Tightening torque: 0.5 Nm; Shielded connection cable: screen not connected

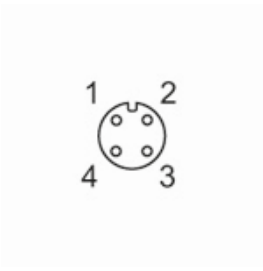

Connection

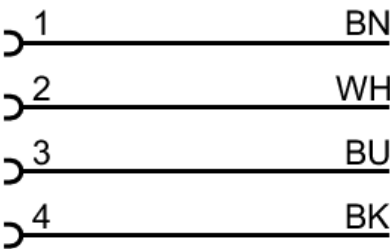

BN =	Core colours :
BK =	brown
BU =	black
WH =	blue
	white