


# E10790




## Wirable socket

SDOAH040MSSFKPG

Article no longer available - archive entry

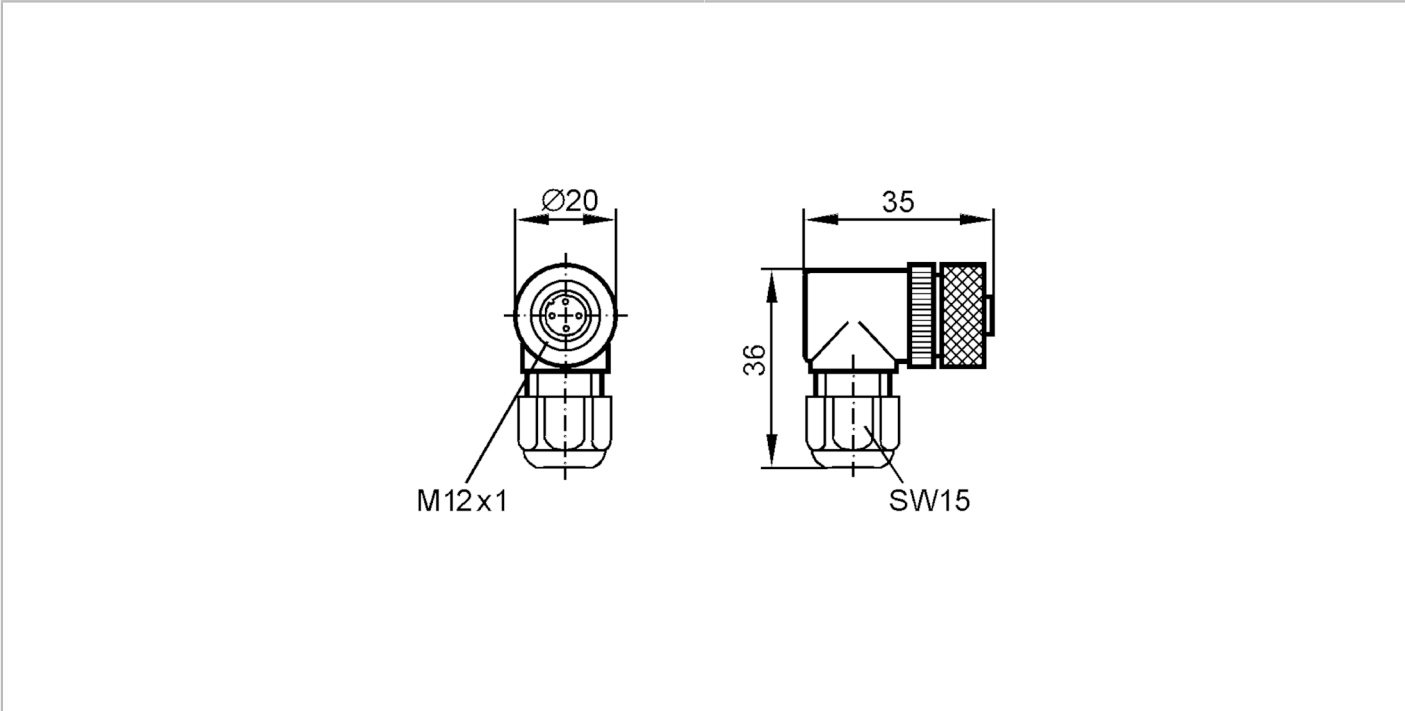

| Electrical data                                                                        |      |                      |
|----------------------------------------------------------------------------------------|------|----------------------|
| Operating voltage                                                                      | [V]  | < 125 AC / < 150 DC  |
| Operating conditions                                                                   |      |                      |
| Ambient temperature                                                                    | [°C] | -25...90             |
| Protection                                                                             |      | IP 67                |
| Mechanical data                                                                        |      |                      |
| Dimensions                                                                             | [mm] | 36 x 20 x 35         |
| Materials                                                                              |      | PA                   |
| Moulded-body material                                                                  |      | PA                   |
| Material nut                                                                           |      | brass, nickel-plated |
| Remarks                                                                                |      |                      |
| Pack quantity                                                                          |      | 1 pcs.               |
| Electrical connection                                                                  |      |                      |
| terminals: ...0.75 mm²; Cable gland: PG 7                                              |      |                      |
| Electrical connection - socket                                                         |      |                      |
| Connector: 1 x M12, angled; coding: A; Moulded body: PA; Locking: brass, nickel-plated |      |                      |

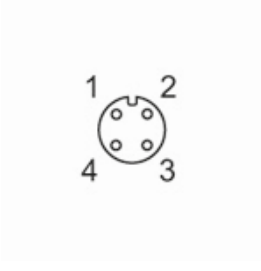

# E10790

## Wirable socket

SDOAH040MSSFKPG



### Connection

