

# E10818



## Jumper cable with valve plug

VVSAB041MSS00,6A03STAH030VAS



| Application                   |           |                               |
|-------------------------------|-----------|-------------------------------|
| Special feature               |           | Halogen-free                  |
| Electrical data               |           |                               |
| Operating voltage             | [V]       | < 24 AC/DC                    |
| Oversvoltage protection       |           | yes; (VDR)                    |
| Operating conditions          |           |                               |
| Ambient temperature           | [°C]      | -25...90                      |
| Protection                    |           | IP 67                         |
| Mechanical data               |           |                               |
| Weight                        | [g]       | 76                            |
| Dimensions                    | [mm]      | 30 x 15 x 39                  |
| Materials                     |           | TPU                           |
| Moulded-body material         |           | TPU                           |
| Material nut                  |           | stainless steel (316L/1.4404) |
| Displays / operating elements |           |                               |
| Display                       | operation | 1 x LED, yellow               |

# E10818



## Jumper cable with valve plug

VVSAB041MSS00,6A03STAH030VAS

### Accessories

Items supplied

screw

panel for labelling

 
### Remarks

Pack quantity

1 pcs.

### Electrical connection - plug


Connector: 1 x M12, angled; coding: A; Moulded body: TPU; Locking: stainless steel (316L/1.4404)



### Electrical connection

Cable: 0.6 m, PUR, Halogen-free, black, Ø 4.8 mm; 3 x 0.5 mm<sup>2</sup> (16 x Ø 0.2 mm)

### Connection

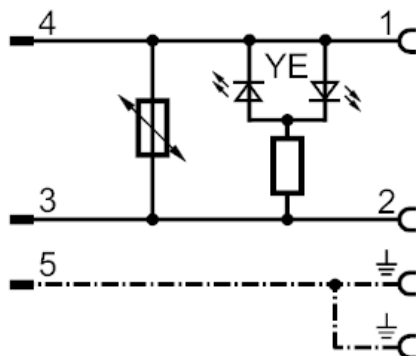

### Electrical connection - socket

Connector: 1 x valve type A DIN, angled; Moulded body: TPU; Locking: stainless steel (316L/1.4404)

