


Connection cable

VDOAH043MSS0002I04STGH040MSS

Article no longer available - archive entry

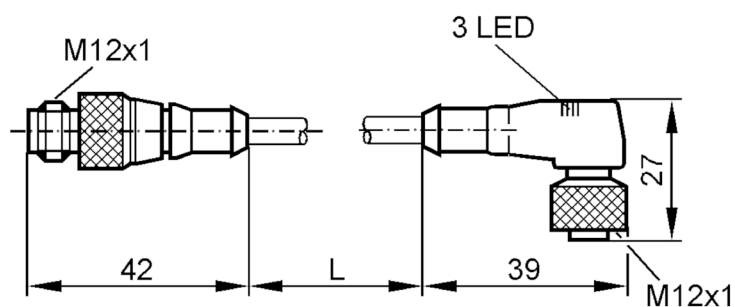

Application

Special feature

Halogen-free

Electrical data

Operating voltage

[V]

10...30 DC

Operating conditions

Ambient temperature

[°C]

-25...90

Protection

IP 67

Mechanical data

Materials

TPU

Moulded-body material

TPU

Material nut

brass, nickel-plated

Displays / operating elements

Display

switching status

2 x LED, yellow

operation

1 x LED, green

Remarks

Pack quantity

1 pcs.

E10876



Connection cable

VDOAH043MSS0002I04STGH040MSS

Electrical connection - plug

Connector: 1 x M12, straight; coding: A; Moulded body: TPU; Locking: brass, nickel-plated; Tightening torque: 0.5 Nm



Electrical connection

Cable: 2 m, PUR, Halogen-free; cross-linked; 4 x 0.34 mm² (19 x Ø 0.15 mm)

Connection



Electrical connection - socket

Connector: 1 x M12, angled; coding: A; Moulded body: TPU; Locking: brass, nickel-plated; Tightening torque: 0.5 Nm

