

E10920




Splitter box

ZDO4F035MSS0000-00STAF070MSS

Article no longer available - archive entry

Alternative articles: EBC050

When selecting an alternative article and accessories please note that technical data may differ!

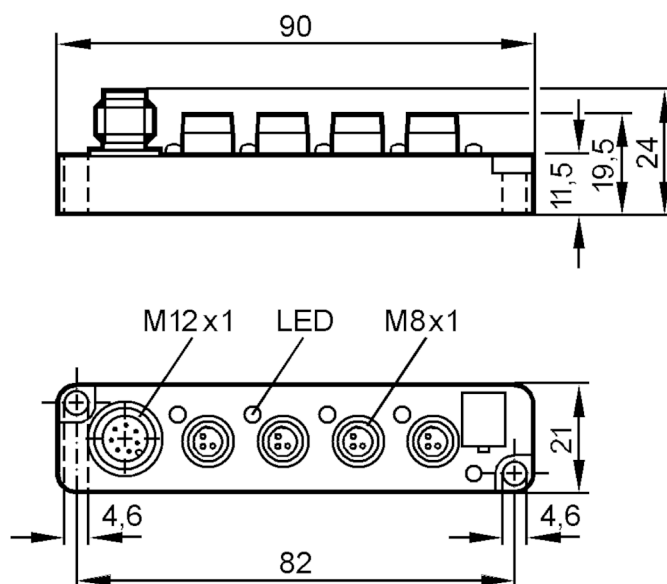

Application

Special feature	Free from silicone; Gold-plated contacts
Free from silicone	yes

Electrical data

Operating voltage	[V]	10...30 DC
Max. current load per module/slot	[A]	2
Max. current load total	[A]	4

Operating conditions

Ambient temperature	[°C]	-15...90
Protection		IP 67

Mechanical data

Number of ports splitter box	4
Connector type	M8

Displays / operating elements

Display	switching status	4 x LED, yellow
	operation	1 x LED, green

Remarks

Pack quantity	1 pcs.
---------------	--------




Splitter box


ZDO4F035MSS0000-00STAF070MSS

Electrical connection - Connection

Connector: 1 x M12; coding: A; Contacts: gold-plated; Tightening torque: 0.5 Nm

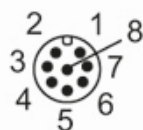

Connection

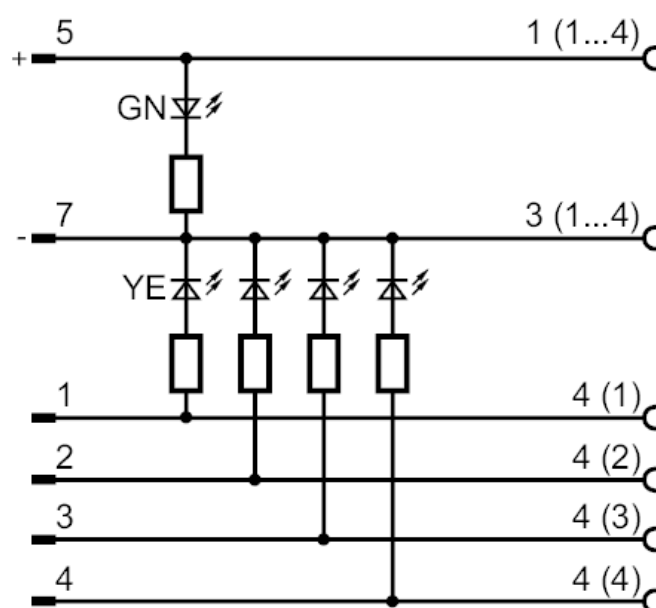

Electrical connection - slot

Connector: 4 x M8; coding: A; Contacts: gold-plated; Tightening torque: 0.5 Nm

