


Connecting cable with socket

ADOGH080MSS0010A06

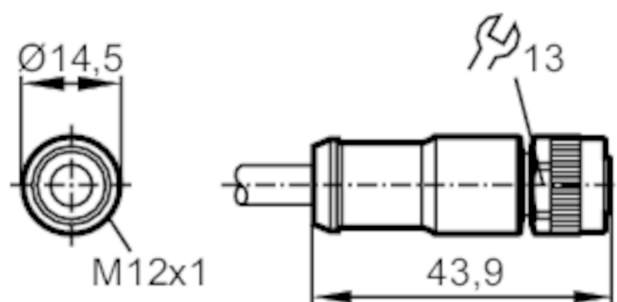

Electrical data

Operating voltage	[V]	< 60 AC/DC
Max. current load total	[A]	2

Operating conditions

Ambient temperature	[°C]	-25...85
Protection		IP 68

Mechanical data

Weight	[g]	468.7
Dimensions	[mm]	14.5 x 14.5 x 43.9
Materials		TPU
Moulded-body material		TPU
Material nut		diecast zinc, nickel-plated

Remarks

Pack quantity	1 pcs.
---------------	--------

E10977



Connecting cable with socket

ADOGH080MSS0010A06

Electrical connection


Cable: 10 m, PUR, black, Ø 6 mm; 6 x 0.34 mm² (42 x Ø 0.1 mm)

Electrical connection - socket

Connector: 1 x M12, straight; coding: A; Moulded body: TPU; Locking: diecast zinc, nickel-plated



Connection

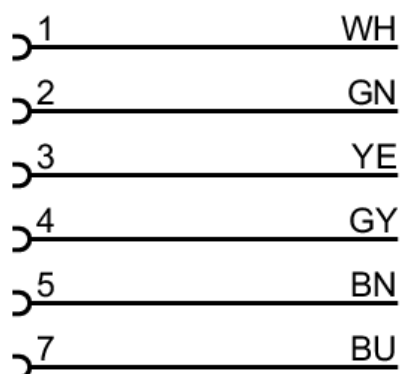

Core colours :
BN = brown
BU = blue
GN = green
GY = grey
WH = white
YE = yellow