


E10154



Limit plunger

LIMIT PLUNGERS IE

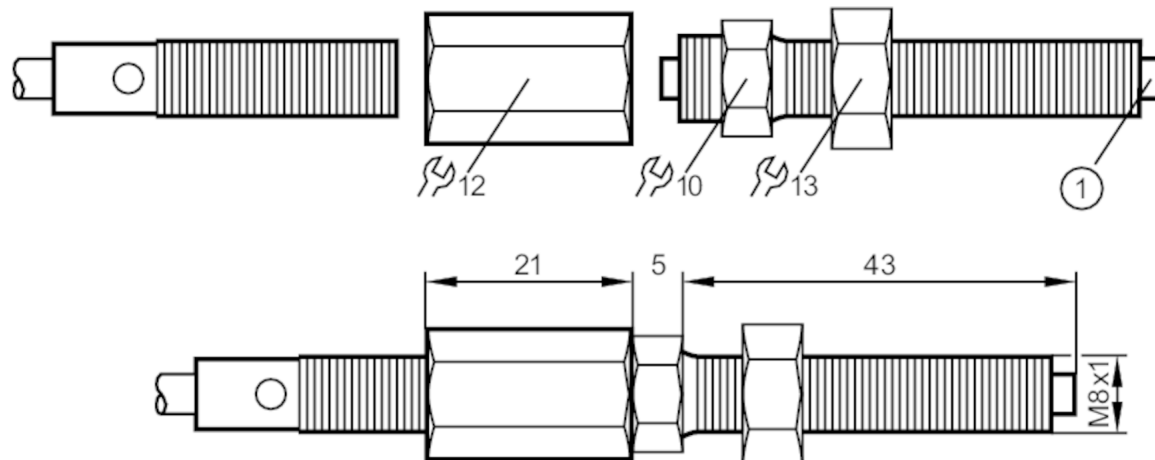

1 movable bolt with spring return stroke 1.5mm, Ø 5.5mm

Application

Design

for types, M8 x 1, Sn = 1 mm b, 2 mm b

Mechanical data

Weight

[g]

36.6

Materials

Limit plunger: free cutting steel; plunger: steel (1.0503 / C45K) hardened on front; Lock nut: brass nickel-plated

Activation force

[N]

4.9...7845

Remarks

Pack quantity

1 pcs.