


# E11248



## Connecting cable with socket

ADOAA050MSS0005H04

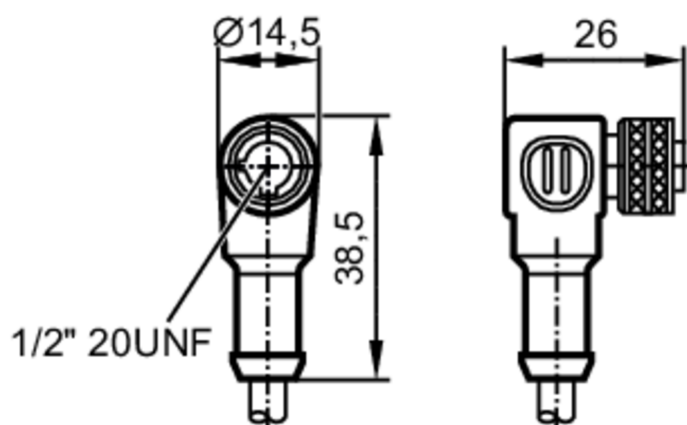

| Application           |      |                      |
|-----------------------|------|----------------------|
| Special feature       |      | Halogen-free         |
| Electrical data       |      |                      |
| Operating voltage     | [V]  | < 300 AC             |
| Operating conditions  |      |                      |
| Ambient temperature   | [°C] | -25...90             |
| Protection            |      | IP 67                |
| Mechanical data       |      |                      |
| Weight                | [g]  | 165.2                |
| Materials             |      | TPU                  |
| Moulded-body material |      | TPU                  |
| Material nut          |      | brass, nickel-plated |
| Remarks               |      |                      |
| Pack quantity         |      | 1 pcs.               |

# E11248



## Connecting cable with socket

ADOAA050MSS0005H04

### Electrical connection


Cable: 5 m, PUR, Halogen-free, black, Ø 4.7 mm; 4 x 0.34 mm<sup>2</sup> (43 x Ø 0.1 mm )

### Electrical connection - socket

Connector: 1 x 1/2", angled; coding: C; Moulded body: TPU; Locking: brass, nickel-plated



### Connection

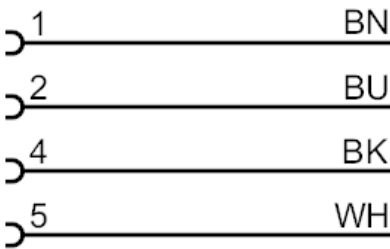

|      |                |
|------|----------------|
|      | Core colours : |
| BK = | black          |
| BN = | brown          |
| BU = | blue           |
| WH = | white          |