


E12500



Wirable plug

SSTGH040ZDSFKG

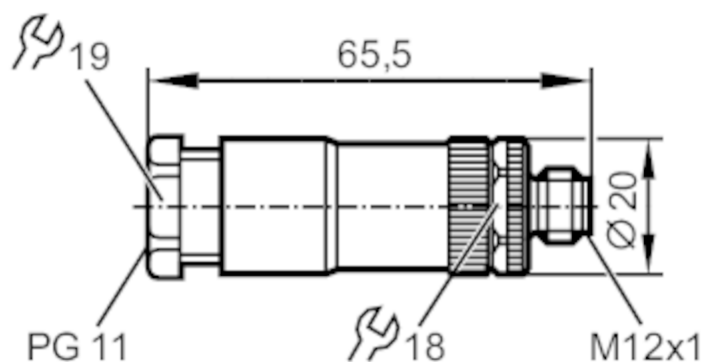

Application

Special feature	Free from silicone; Gold-plated contacts
Design	power cable, T-coded
Free from silicone	yes

Electrical data

Operating voltage	[V]	< 60 DC
Max. current load total	[A]	12; (when using conductors with 1.5 mm ²)

Operating conditions

Ambient temperature	[°C]	-40...85
Protection		IP 67

Mechanical data

Weight	[g]	25.7
Dimensions	[mm]	20 x 20 x 65.5
Moulded-body material		PA
Material nut		diecast zinc
Sealing material		NBR

Remarks

Pack quantity		1 pcs.
---------------	--	--------

E12500



Wirable plug

SSTGH040ZDSFKG

Electrical connection

screw terminals: 0.75...1.5 mm²; Cable sheath: Ø 8...10 mm

Electrical connection - plug

Connector: 1 x M12, straight; coding: T; Moulded body: PA; Locking: diecast zinc; Sealing: NBR; Contacts: gold-plated; Tightening torque: 0.4 Nm



Connection

