


Adapter socket

EDOGH050MSS0,15E05 (M16)

Article no longer available - archive entry

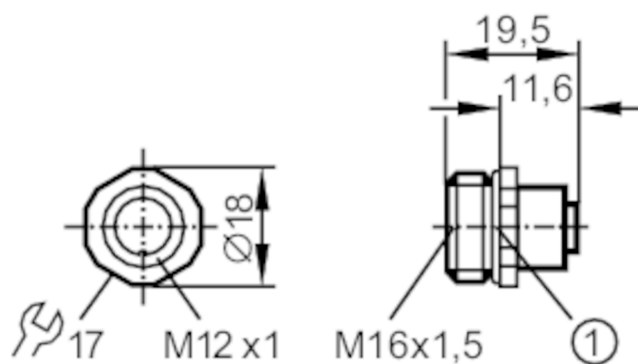

1 O-ring

Electrical data

Operating voltage	[V]	< 30 AC / < 36 DC
Max. current load total	[A]	4

Operating conditions

Ambient temperature	[°C]	-25...90
Protection		IP 68

Mechanical data

Weight	[g]	21.7
Mounting thread		M16
Materials		brass nickel-plated
Moulded-body material		brass, nickel-plated

Remarks

Pack quantity		1 pcs.
---------------	--	--------

E12048



Adapter socket


EDOGH050MSS0,15E05 (M16)

Electrical connection

Cable: 0.15 m, PVC; 5 x 0.34 mm²

Electrical connection - socket

Connector: 1 x M12; coding: A; Moulded body: brass, nickel-plated

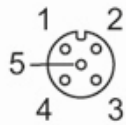

Connection

1	BN
2	WH
3	BU
4	BK
5	GY

	Core colours :
BK =	black
BN =	brown
BU =	blue
GY =	grey
WH =	white