


E18056



Adapter plug

RSTGB050VAS00.3-05

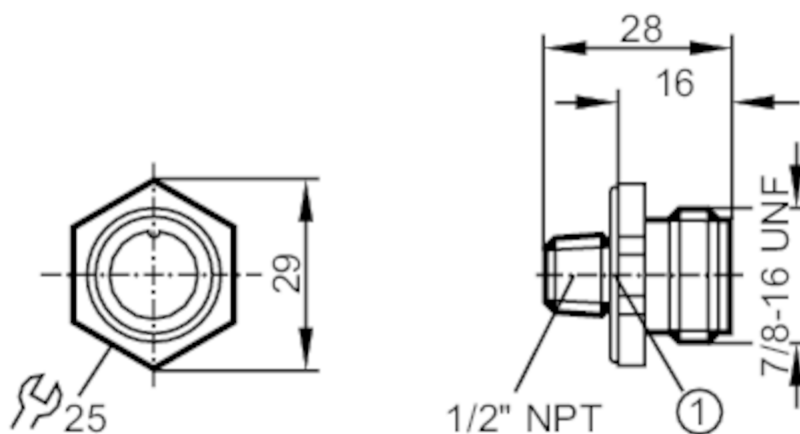

1 O-ring

Application

Special feature

Gold-plated contacts

Electrical data

Operating voltage

[V]

< 600 AC/DC

Operating conditions

Ambient temperature

[°C]

-20...100

Protection

IP 68

Mechanical data

Weight

[g]

63.503

Mounting thread

1/2" NPT

Materials

stainless steel anodised

Moulded-body material

stainless steel, anodised

Remarks

Pack quantity

1 pcs.

E18056



Adapter plug


RSTGB050VAS00.3-05

Electrical connection

Cable: 0.3 m, PVC; 5 x 1.5 mm² / AWG 16

Electrical connection - plug

Connector: 1 x 7/8", straight; coding: A; Moulded body: stainless steel, anodised; Contacts: gold-plated

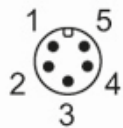

Connection

1	WH
2	RD
3	BN/YE
4	OG
5	BK

GN =	Core colours :
GN/YE =	green
RD =	green/yellow
OG =	red
WH =	orange
	white