


E18160



Connecting cable with socket

ADOAH040VAS0075E04

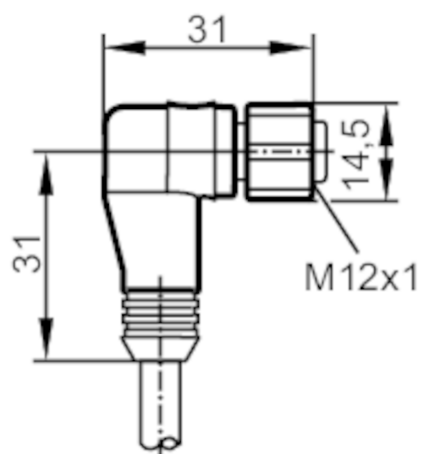

Application

Special feature

Gold-plated contacts

Electrical data

Operating voltage

[V]

< 300 AC/DC

Operating conditions

Ambient temperature

[°C]

-20...105

Protection

IP 68

Mechanical data

Weight

[g]

2685.265

Dimensions

[mm]

31 x 14.5 x 31

Materials

PVC

Moulded-body material

PVC

Material nut

stainless steel (316Ti/1.4571)

Remarks

Pack quantity

1 pcs.

E18160



Connecting cable with socket


ADOAH040VAS0075E04

Electrical connection

Cable: 75 m, PVC, grey; 4 x 0.34 mm² / AWG 22

Electrical connection - socket

Connector: 1 x M12, angled; coding: A; Moulded body: PVC; Locking: stainless steel (316Ti/1.4571); Contacts: gold-plated

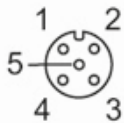

Connection



- 5: not used
Core colours :
BK = black
BN = brown
BU = blue
WH = white