




Fibre optic diffuse reflection sensor

FT-00-A-A-R4/1,5

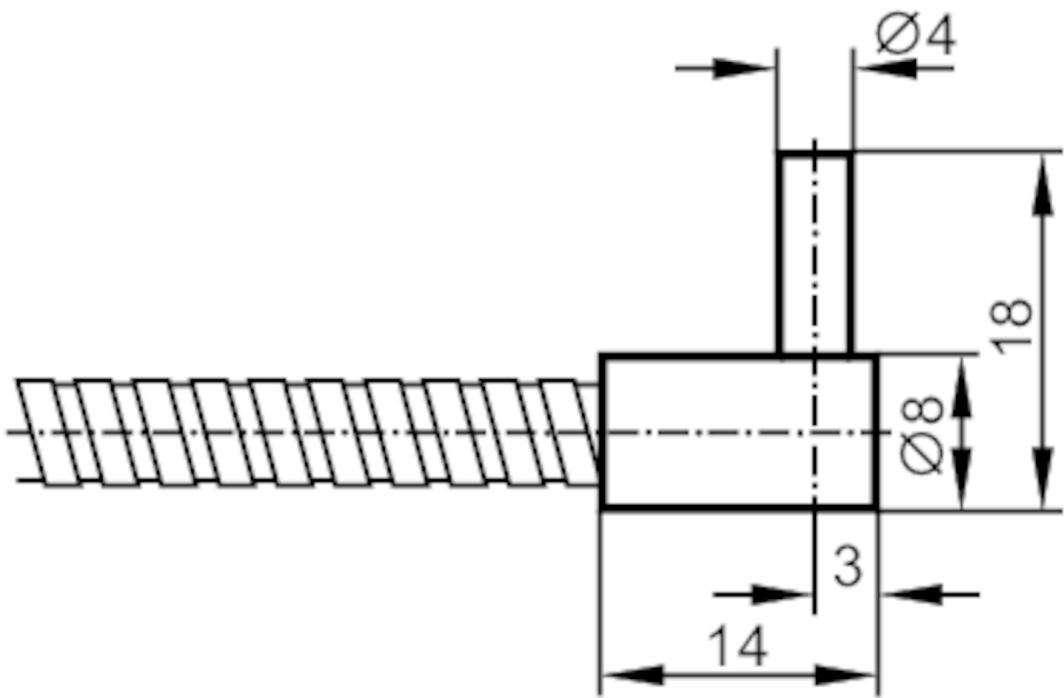

Application		
Function principle		Diffuse reflection sensor
Application		High temperature resistance; Robust design for use in harsh industrial environments
Detection zone		
Range with fibre optic amplifier type		OKF; OUF; OOF
OKF		
Range fibre optics	[mm]	36
OOF		
Range fibre optics	[mm]	180
OUF		
Range fibre optics	[mm]	36
Operating conditions		
Ambient temperature	[°C]	-40...290
Mechanical data		
Weight	[g]	72
Version of sensing head		angled
Sensing head diameter	[mm]	4
Sensing head length	[mm]	10
Total length	[mm]	1500

E20072



Fibre optic diffuse reflection sensor

FT-00-A-A-R4/1,5

Min. bending radius	[mm]	20; (for fixed installation)
Fibre arrangement		
Materials		Adapter: ABS
Fibre material		glass
Fibre head material		aluminium
Fibre sheath material		aluminium
Accessories		
Items supplied		Mounting clamp:, E10221
Remarks		
Pack quantity		1 pcs.