


## Fibre optic diffuse reflection sensor

FT-00-N-V-M6/S

Article no longer available - archive entry

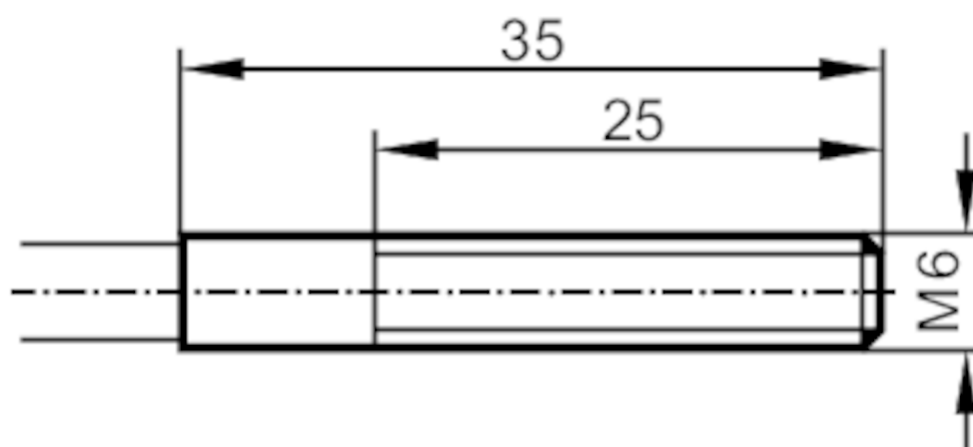

## Application

Function principle

Diffuse reflection sensor

## Detection zone

Range with fibre optic  
amplifier type

OKF; OUF

## OKF

Range fibre optics

[mm]

40

## OUF

Range fibre optics

[mm]

40

## Operating conditions

Ambient temperature

[°C]

-20...140

## Mechanical data

Version of sensing head

straight

Sensing head thread

M6

Sensing head length

[mm]

35

Total length

[mm]

600

Min. bending radius

[mm]

20

Materials

Adapter: ABS

Fibre material

glass

E20380



Fibre optic diffuse reflection sensor

FT-00-N-V-M6/S

|                       |                              |
|-----------------------|------------------------------|
| Fibre head material   | stainless steel (303/1.4305) |
| Fibre sheath material | FKM                          |
| Remarks               |                              |
| Pack quantity         | 1 pcs.                       |