


Connecting cable with plug

ASTAB040PLS0005E04

Article no longer available - archive entry

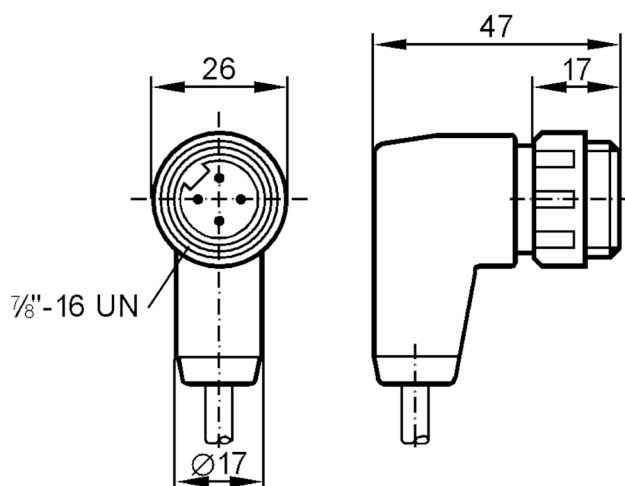

Electrical data

Operating voltage	[V]	< 250 AC / 10...55 DC
-------------------	-----	-----------------------

Operating conditions

Ambient temperature	[°C]	-25...90
---------------------	------	----------

Protection		IP 67
------------	--	-------

Mechanical data

Materials		TPU
-----------	--	-----

Moulded-body material		TPU
-----------------------	--	-----

Material nut		PA
--------------	--	----

Remarks

Remarks		pin 2 leading
---------	--	---------------

Pack quantity		1 pcs.
---------------	--	--------

Electrical connection

Cable: 5 m, PVC, orange, Ø 6.3 mm; 4 x 0.5 mm² (16 x Ø 0.2 mm)

Electrical connection - plug

Connector: 1 x 7/8", angled; coding: A; Moulded body: TPU; Locking: PA; Tightening torque: 0.5 Nm



E70174



Connecting cable with plug

ASTAB040PLS0005E04

Connection

1	BN
2	WH
3	BU
4	BK

	Core colours :
BK =	black
BN =	brown
BU =	blue
WH =	white