


E80409



RFID tag

ID-TAG/86 x 54 /04

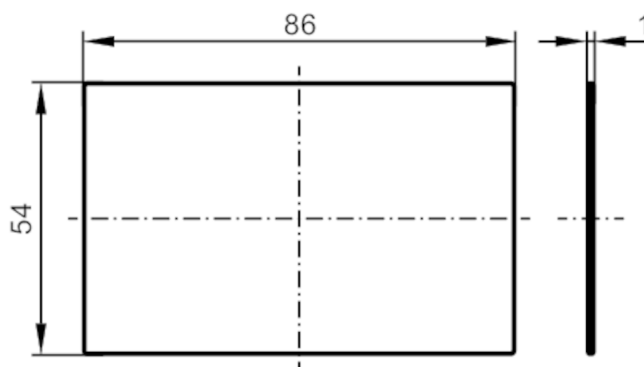

Electrical data

Operating frequency	[MHz]	860...960
Memory size	[bit]	192
Memory type		EEPROM
Chip type		Impinj Monza 4QT
Electronic product code (EPC)		96-128 Bits; (User: 32-64 Bits)
RFID standard		EPC Class1 GEN2/ISO 18000-6C
Max. read cycles		unlimited
Max. write cycles		100000

Operating conditions

Ambient temperature	[°C]	-35...50
---------------------	------	----------

Mechanical data

Weight	[g]	49.1
Dimensions	[mm]	54 x 85.6 x 0.76
Materials		housing: PVC

Remarks

Pack quantity		10 pcs.
---------------	--	---------

Other data

read distance (m)

DTE80x	1.8
DTE90x	1.1
ANT860 / ANT960	4.8
ANT820 / ANT920	1.5