


# EVT071

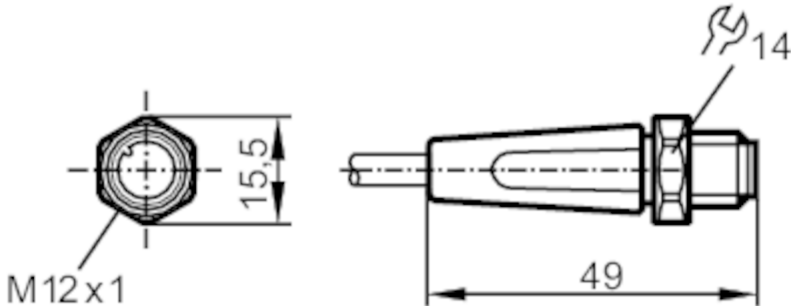

## Connecting cable with plug

ASTGH040VAS0002E04



| Application                                                     |      |                                                                  |
|-----------------------------------------------------------------|------|------------------------------------------------------------------|
| Special feature                                                 |      | Free from silicone; Gold-plated contacts; Drag chain suitability |
| Application                                                     |      | hygienic and wet areas in the food industry                      |
| Free from silicone                                              |      | yes                                                              |
| Electrical data                                                 |      |                                                                  |
| Operating voltage                                               | [V]  | < 250 AC / < 300 DC                                              |
| Protection class                                                |      | II                                                               |
| Max. current load total                                         | [A]  | 4                                                                |
| Operating conditions                                            |      |                                                                  |
| Ambient temperature                                             | [°C] | -25...100                                                        |
| Note on ambient temperature                                     |      | cULus: ...50 °C                                                  |
| Ambient temperature (moving)                                    | [°C] | 5...100                                                          |
| Note on ambient temperature (moving)                            |      | cULus: ...50 °C                                                  |
| Storage temperature                                             | [°C] | -25...55                                                         |
| Storage humidity                                                | [%]  | 10...100                                                         |
| Other climatic conditions for storage according to stated class |      | 1K22/ DIN 60721-3-1                                              |
| Protection                                                      |      | IP 65; IP 67; IP 68; IP 69K                                      |
| Mechanical data                                                 |      |                                                                  |
| Weight                                                          | [g]  | 112.5                                                            |
| Dimensions                                                      | [mm] | 15.5 x 15.5 x 49                                                 |
| Materials                                                       |      | housing: PVC orange                                              |



## Connecting cable with plug

ASTGH040VAS0002E04

|                        |                                 |                                                                                    |
|------------------------|---------------------------------|------------------------------------------------------------------------------------|
| Material nut           | stainless steel (316L/1.4404)   |                                                                                    |
| Drag chain suitability | yes                             |                                                                                    |
| Drag chain suitability | bending radius for flexible use | min. 10 x cable diameter                                                           |
|                        | travel speed                    | max. 3.3 m/s for a horizontal travel length of 5 m and max. acceleration of 5 m/s² |
|                        | bending cycles                  | > 1 Mio.                                                                           |
|                        | torsional strain                | ± 180 °/m                                                                          |

## Remarks

|               |        |
|---------------|--------|
| Pack quantity | 1 pcs. |
|---------------|--------|

## Electrical connection

Cable: 2 m, PVC, orange, Ø 4.9 mm; 4 x 0.34 mm² (42 x Ø 0.1 mm )

## Electrical connection - plug

Connector: 1 x M12, straight; coding: A; Locking: stainless steel (316L/1.4404); Contacts: gold-plated; Tightening torque: 0.6...1.5 Nm



## Connection

|   |    |
|---|----|
| 1 | BN |
| 2 | WH |
| 3 | BU |
| 4 | BK |

Core colours :

BK = black

BN = brown

BU = blue

WH = white