

OIT-FPKG





Diffuse reflection sensor

OIT-FPKG

Max. light spot diameter	[mm]	122
Light spot dimensions refer to		at maximum range

Operating conditions

Ambient temperature	[°C]	-25...80
Protection		IP 65

Tests / approvals

EMC	EN 60947-5-2	
	EN 55011	class B
MTTF	[years]	659

Mechanical data

Weight	[g]	125.5
Housing		threaded type
Dimensions	[mm]	M30 x 1.5 / L = 125
Thread designation		M30 x 1.5
Materials		PBT; PPO modified
Lens material		PMMA

Displays / operating elements

Display	switching status	1 x LED, yellow
---------	------------------	-----------------

Accessories

Items supplied	lock nuts: 2
	screwdrivers


Remarks

Pack quantity	1 pcs.
---------------	--------

Electrical connection

terminals: ...1.5 mm²; Cable sheath: Ø 7...13 mm; Cable gland: M20 X 1.5

Connection

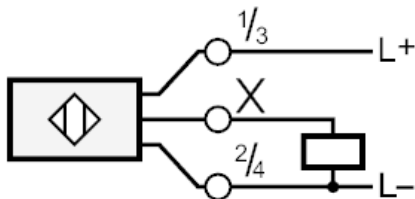



Diffuse reflection sensor

OIT-FPKG

Diagrams and graphs

excess gain graph

