

# E10422




## Connecting cable with socket

ADOAH042MSS0002A04

Article no longer available - archive entry

Alternative articles: EVC007  
When selecting an alternative article and accessories please note that technical data may differ!

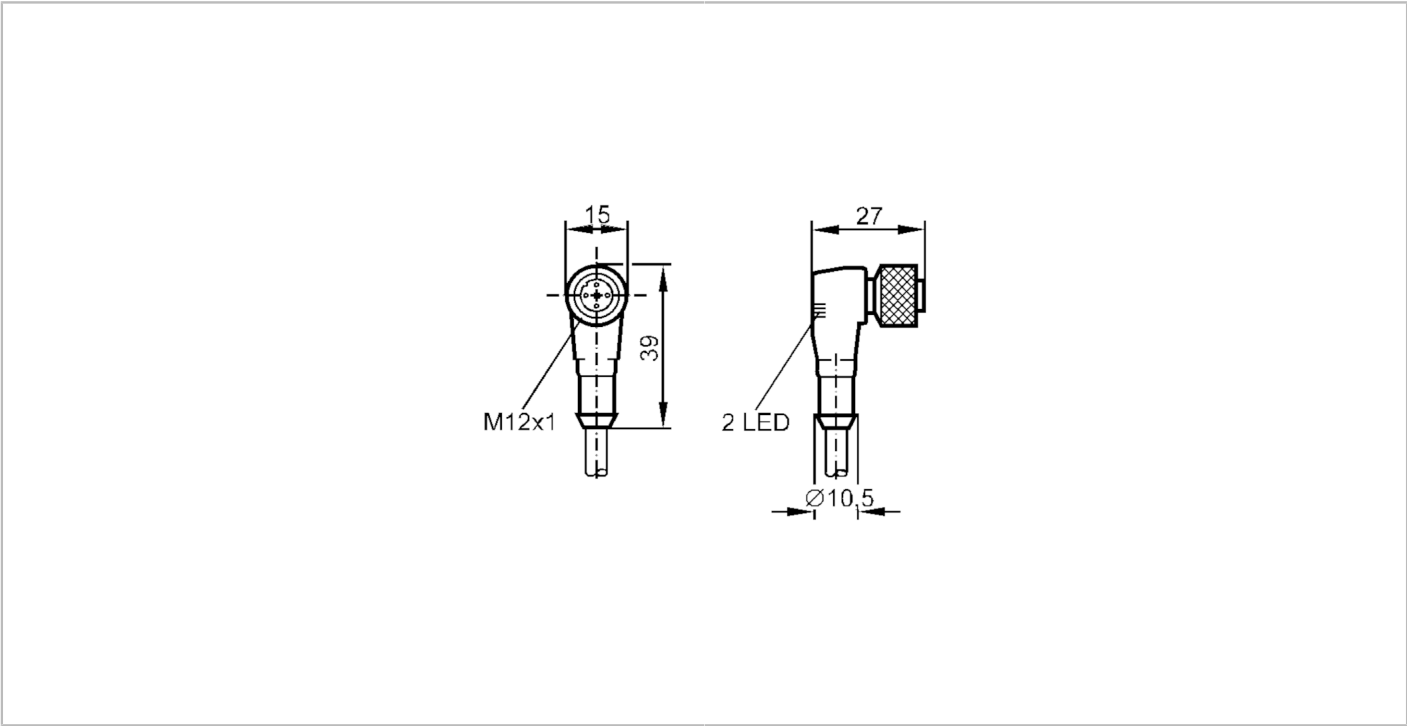

| Electrical data               |                  |                      |
|-------------------------------|------------------|----------------------|
| Operating voltage             | [V]              | 10...30 DC           |
| Outputs                       |                  |                      |
| Electrical design             |                  | PNP                  |
| Operating conditions          |                  |                      |
| Ambient temperature           | [°C]             | -25...90             |
| Protection                    |                  | IP 67                |
| Mechanical data               |                  |                      |
| Dimensions                    | [mm]             | 27 x 15 x 39         |
| Materials                     |                  | TPU transparent      |
| Moulded-body material         |                  | TPU, transparent     |
| Material nut                  |                  | brass, nickel-plated |
| Displays / operating elements |                  |                      |
| Display                       | switching status | 1 x LED, yellow      |
|                               | operation        | 1 x LED, green       |
| Remarks                       |                  |                      |
| Pack quantity                 |                  | 1 pcs.               |

# E10422



## Connecting cable with socket

ADOAH042MSS0002A04

### Electrical connection


Cable: 2 m, PUR / PVC, orange, Ø 5 mm; 4 x 0.25 mm<sup>2</sup> (32 x Ø 0.1 mm )

### Electrical connection - socket

Connector: 1 x M12, angled; coding: A; Moulded body: TPU, transparent; Locking: brass, nickel-plated; Tightening torque: 0.5 Nm



### Connection

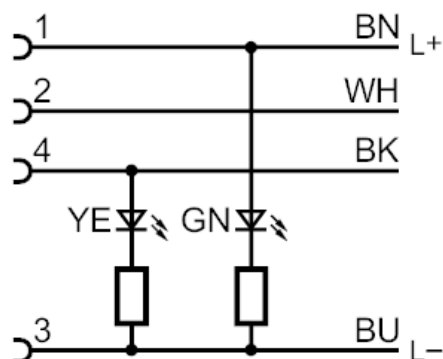

|      |                |
|------|----------------|
| BN = | Core colours : |
| BK = | brown          |
| BU = | black          |
| WH = | blue           |
|      | white          |