


E10537



Connecting cable with socket

ADOGF030MSS0002E03

Article no longer available - archive entry

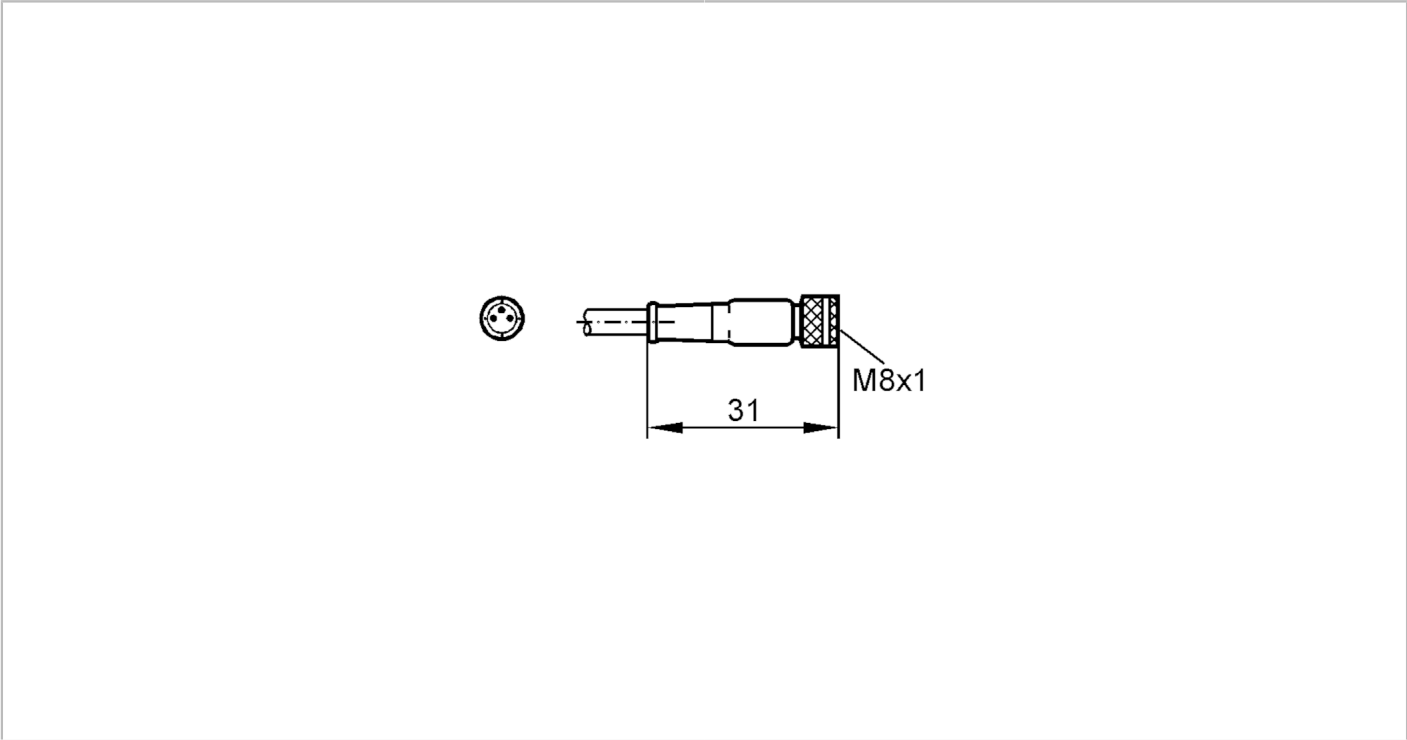

Electrical data		
Operating voltage	[V]	< 60 AC / < 75 DC
Protection class		III
Operating conditions		
Ambient temperature	[°C]	-25...90
Protection		IP 67
Mechanical data		
Materials		TPU
Moulded-body material		TPU
Material nut		brass, nickel-plated
Remarks		
Pack quantity		1 pcs.

E10537



Connecting cable with socket

ADOGF030MSS0002E03

 
Electrical connection

Cable: 2 m, PVC, orange, Ø 5 mm; 3 x 0.34 mm² (42 x Ø 0.1 mm)


Electrical connection - socket

Connector: 1 x M8, straight; coding: A; Moulded body: TPU; Locking: brass, nickel-plated

Connector: 1 x M8, straight; coding: A; Moulded body: TPU; Locking: brass, nickel-plated



Connection

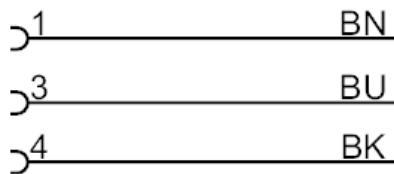

BK =	Core colours :
BN =	black
BU =	brown
	blue