


E10681



Connecting cable with socket

ADOGH042MSS0010B04

Article no longer available - archive entry

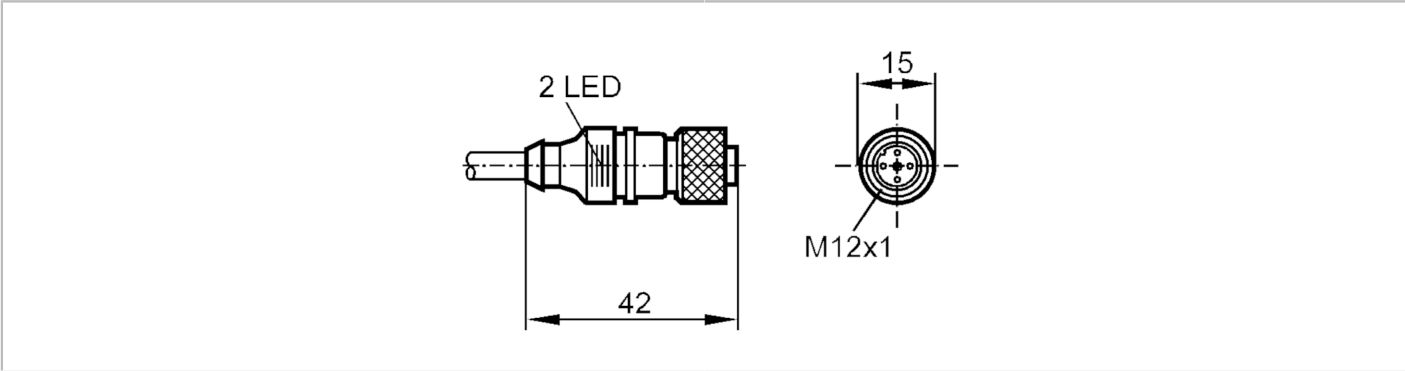

Electrical data

Operating voltage	[M]	10...30 DC
-------------------	-----	------------

Outputs

Electrical design	NPN
-------------------	-----

Operating conditions

Ambient temperature	[°C]	-25...90
---------------------	------	----------

Protection	IP 67
------------	-------

Mechanical data

Dimensions	[mm]	15 x 15 x 42
------------	------	--------------

Materials	TPU
-----------	-----

Moulded-body material	TPU
-----------------------	-----

Material nut	brass, nickel-plated
--------------	----------------------

Displays / operating elements

Display	switching status	1 x LED, yellow
	operation	1 x LED, green

Remarks

Pack quantity	1 pcs.
---------------	--------

Electrical connection

Cable: 10 m, PUR; 4 x 0.25 mm² (128 x Ø 0.05 mm)

Electrical connection - socket

Connector: 1 x M12, straight; coding: A; Moulded body: TPU; Locking: brass, nickel-plated




E10681



Connecting cable with socket

ADOGH042MSS0010B04

Connection

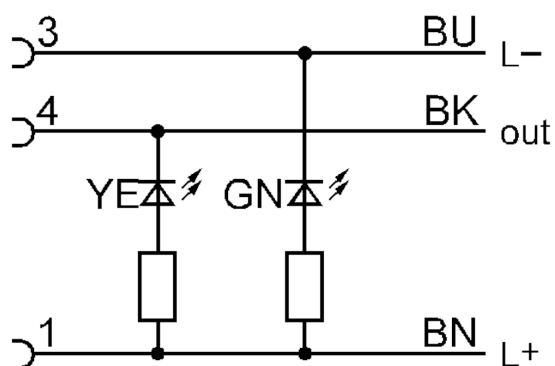

BK =
BN =
BU =

Core colours :
black
brown
blue