




Wirable socket

SDOGA030MSSFKPG

Article no longer available - archive entry

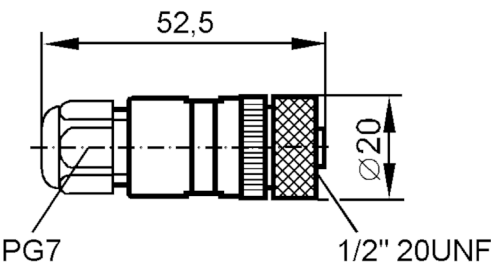

Electrical data

Operating voltage	[V]	< 250 AC
-------------------	-----	----------

Operating conditions

Ambient temperature	[°C]	-25...90
Protection		IP 67

Mechanical data

Weight	[g]	25
Dimensions	[mm]	20 x 20 x 52.5
Materials		PA
Moulded-body material		PA
Material nut		brass, nickel-plated

Remarks


Pack quantity		1 pcs.
---------------	--	--------

Electrical connection

terminals: ...0.75 mm²	
------------------------	--

Electrical connection - socket

 Connector: 1 x 1/2", straight; coding: C; Moulded body: PA; Locking: brass, nickel-plated



E10789

Wirable socket

SDOGA030MSSFKPG



Connection

