


E10951



Connection cable

VDOGH040MSS0002H04STGH040MSS

Article no longer available - archive entry

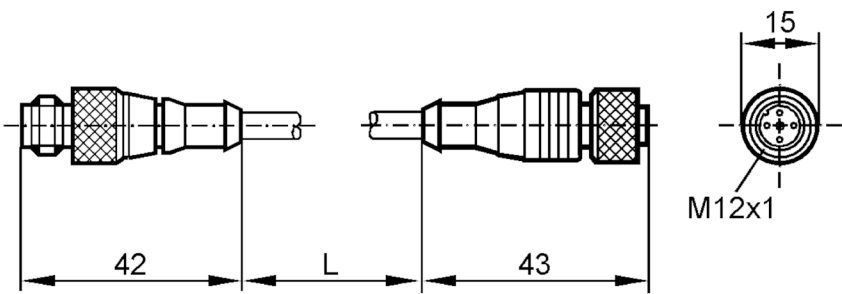

Application	
Special feature	Halogen-free
Electrical data	
Operating voltage	[V] < 250 AC / < 300 DC
Operating conditions	
Ambient temperature	[°C] -25...90
Protection	IP 67
Mechanical data	
Dimensions	[mm] 15 x 15 x 42
Materials	TPU
Moulded-body material	TPU
Material nut	brass, nickel-plated
Remarks	
Pack quantity	1 pcs.

Electrical connection - plug

Connector: 1 x M12, straight; coding: A; Moulded body: TPU; Locking: brass, nickel-plated



E10951



Connection cable

VDOGH040MSS0002H04STGH040MSS

Electrical connection

Cable: 2 m, PUR, Halogen-free; 4 x 0.34 mm²

Connection



Electrical connection - socket

Connector: 1 x M12, straight; coding: A; Moulded body: TPU; Locking: brass, nickel-plated

