




Connection cable

VDOGQ090PLS0003E03STGF040MSS

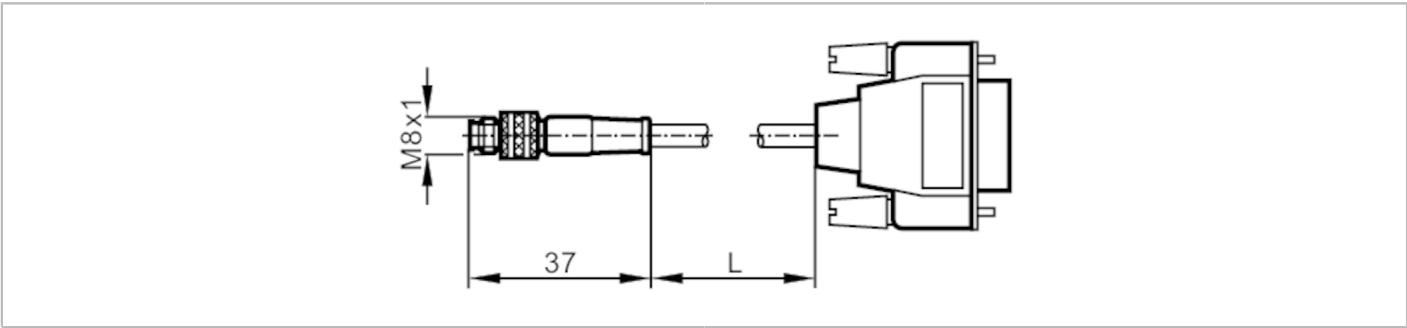

Electrical data

|                   |     |                   |
|-------------------|-----|-------------------|
| Operating voltage | [V] | < 60 AC / < 75 DC |
| Protection class  |     | III               |

Operating conditions

|                     |      |          |
|---------------------|------|----------|
| Ambient temperature | [°C] | -25...85 |
| Protection          |      | IP 50    |

Mechanical data

|                       |     |                      |
|-----------------------|-----|----------------------|
| Weight                | [g] | 113.9                |
| Materials             |     | PUR                  |
| Moulded-body material |     | PUR                  |
| Material nut          |     | brass, nickel-plated |

Remarks

|               |  |        |
|---------------|--|--------|
| Pack quantity |  | 1 pcs. |
|---------------|--|--------|

Electrical connection

Cable: 3 m, PVC, black, Ø 5 mm; 3 x 0.25 mm² (32 x Ø 0.1 mm )

Electrical connection - plug

Connector: 1 x M8, straight; coding: A; Moulded body: PUR; Locking: brass, nickel-plated




# E11572



## Connection cable

VDOGQ090PLS0003E03STGF040MSS

### Connection

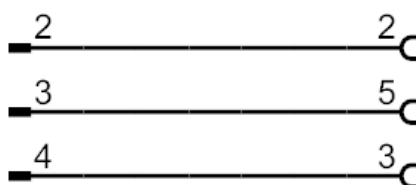

### Electrical connection - socket

Connector: 1 x Sub D, straight; Moulded body: PUR; Locking: brass, nickel-plated

