

E11716




Wirable plug

SSTGH050VASFPKG

Article no longer available - archive entry

Alternative articles: E11859

When selecting an alternative article and accessories please note that technical data may differ!

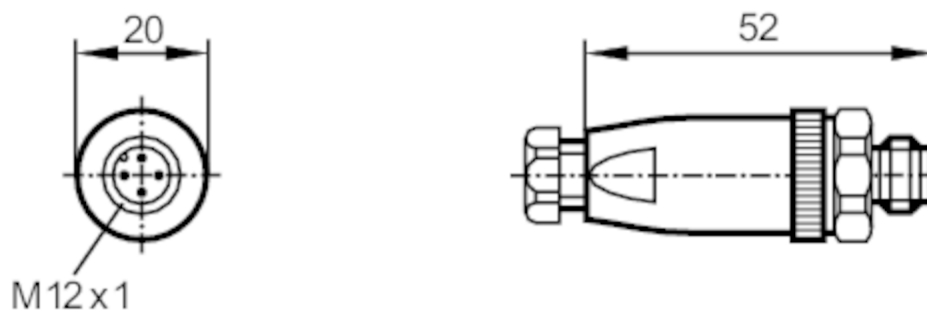

Application

Special feature	Free from silicone; Gold-plated contacts
Free from silicone	yes

Electrical data

Operating voltage	[V]	< 125 AC/DC
Max. current load total	[A]	4; (...40 °C)

Operating conditions

Ambient temperature	[°C]	-40...85
Protection		IP 67

Mechanical data

Dimensions	[mm]	20 x 20 x 52
Materials		PA
Moulded-body material		PA
Material nut		stainless steel (316Ti/1.4571)

Remarks

Pack quantity		1 pcs.
---------------	--	--------

E11716



Wirable plug


SSTGH050VASFPKG

Electrical connection

terminals: ...0.75 mm²; Cable sheath: Ø 6...8 mm

Electrical connection - plug

Connector: 1 x M12, straight; coding: A; Moulded body: PA; Locking: stainless steel (316Ti/1.4571); Contacts: gold-plated

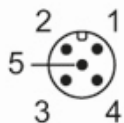

Connection

