


Y connection cable

YDOAH042MSS0001I04STGH040MSS

Article no longer available - archive entry

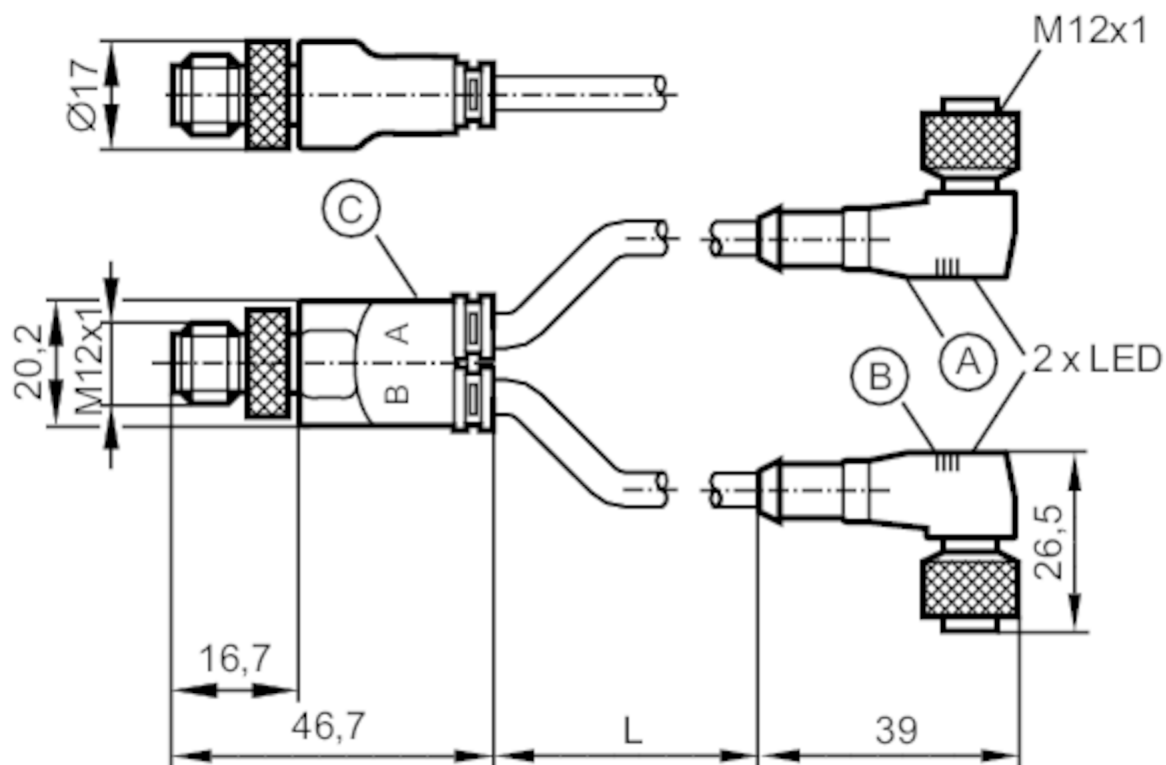

Application

Special feature

Halogen-free

Electrical data

Operating voltage

[V]

10...30 DC

Operating conditions

Ambient temperature

[°C]

-25...90

Protection

IP 67

Mechanical data

Dimensions

[mm]

17 x 20.2 x 46.7

Materials

TPU

Moulded-body material

TPU

Material nut

brass, nickel-plated

Number of ports splitter box

2

Displays / operating elements

Display

switching status

1 x LED, red

operation

1 x LED, green

Remarks

Pack quantity

1 pcs.



Y connection cable

YDOAH042MSS0001I04STGH040MSS

Electrical connection


Cable: 1 m, PUR, Halogen-free, black, Ø 4.3 mm; 3 x 0.34 mm² (43 x Ø 0.1 mm)

Electrical connection - plug

Connector: 1 x M12, straight; coding: A; Moulded body: TPU; Locking: brass, nickel-plated



Connection

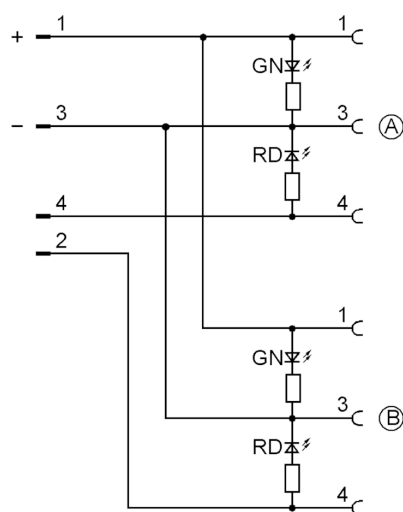

Electrical connection - socket

Connector: 2 x M12, angled; coding: A; Moulded body: TPU; Locking: brass, nickel-plated

