


# E12464



## Wirable socket

SDOGF040MSSFKPG

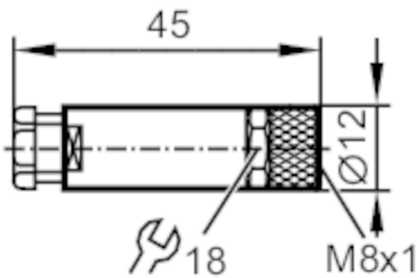

| Application           |      |                      |
|-----------------------|------|----------------------|
| Special feature       |      | Gold-plated contacts |
| Electrical data       |      |                      |
| Operating voltage     | [V]  | < 30 AC/DC           |
| Outputs               |      |                      |
| Electrical design     |      | PNP                  |
| Operating conditions  |      |                      |
| Ambient temperature   | [°C] | -40...85             |
| Protection            |      | IP 67                |
| Mechanical data       |      |                      |
| Weight                | [g]  | 11.2                 |
| Dimensions            | [mm] | 12 x 12 x 45         |
| Materials             |      | PBT; PA              |
| Moulded-body material |      | PBT / PA             |
| Material nut          |      | brass, nickel-plated |
| Remarks               |      |                      |
| Pack quantity         |      | 1 pcs.               |

# E12464



## Wirable socket

SDOGF040MSSFKPG

### Electrical connection

screw terminals: 0.14...0.5 mm<sup>2</sup>; Cable sheath: Ø 3.5...5 mm

### Electrical connection - socket

Connector: 1 x M8, straight; coding: A; Moulded body: PBT / PA; Locking: brass, nickel-plated; Contacts: gold-plated



### Connection

