


E12510



Connecting cable with plug

ASTGN040ZDS0002L04

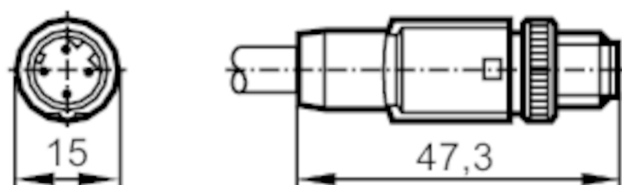

Application

Special feature	Gold-plated contacts
Design	Ethernet cable, D-coded

Electrical data

Operating voltage	[V]	< 250 AC/DC
Max. current load total	[A]	4

Operating conditions

Ambient temperature	[°C]	-40...70
Protection		IP 67

Mechanical data

Weight	[g]	151.5
Dimensions	[mm]	15 x 15 x 47.3
Materials		TPU
Moulded-body material		TPU
Material nut		diecast zinc, nickel-plated

Remarks

Pack quantity		1 pcs.
---------------	--	--------

E12510



Connecting cable with plug

ASTGN040ZDS0002L04

Electrical connection


Cable: 2 m, PVC, green, Ø 6.5 mm; 4 x 0.34 mm²

Electrical connection - plug

Connector: 1 x M12, straight; coding: D; Moulded body: TPU; Locking: diecast zinc, nickel-plated; Contacts: gold-plated; Shielded connection cable: screen connected



Connection

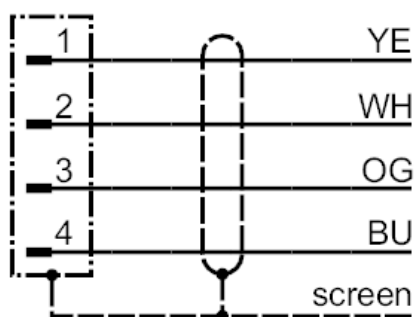

BU =	Core colours :	blue
OG =		orange
WH =		white
YE =		yellow