


Splitter box

ZDO8H05HMSS0020B19

Article no longer available - archive entry

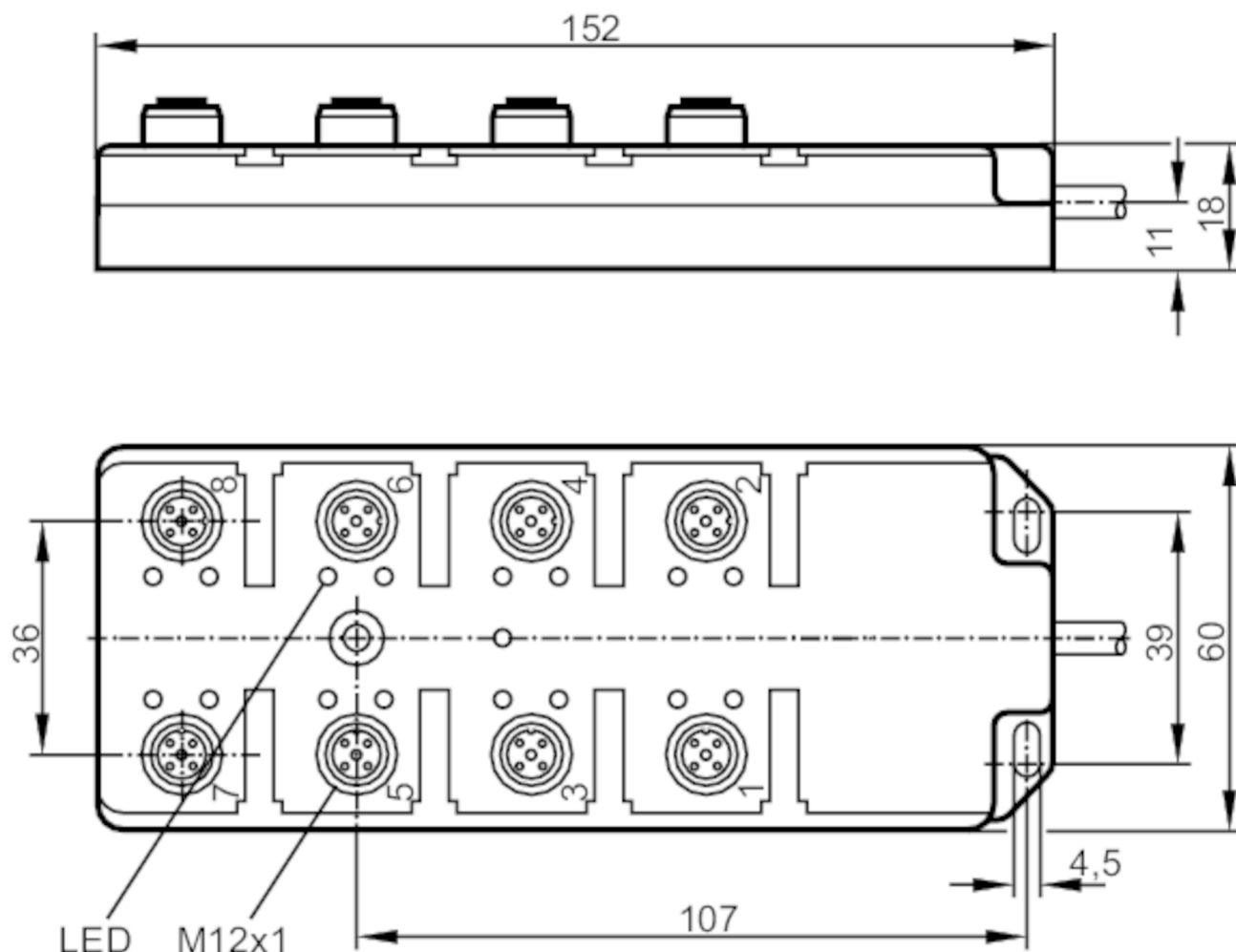

Application

Special feature	Free from silicone; Halogen-free; Gold-plated contacts
Free from silicone	yes

Electrical data

Operating voltage	[V]	10...30 DC
Protection class		II
Max. current load per module/slot	[A]	4
Max. current load total	[A]	12

Outputs

Electrical design	PNP
-------------------	-----

Operating conditions


Ambient temperature	[°C]	-15...80
Protection		IP 67

E12071



Splitter box

ZDO8H05HMSS0020B19

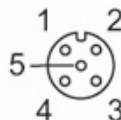Mechanical data		
Materials	TPU	
Moulded-body material	TPU	
Number of ports splitter box	8	
Connector type	M12	
Displays / operating elements		
Display	switching status	16 x LED, yellow
	operation	1 x LED, green
Remarks		
Pack quantity	1 pcs.	
Electrical connection		
Cable: 20 m, PUR, Halogen-free, black, Ø 11.6 mm; 16 x 0.5 mm² (63 x Ø 0.1 mm) + 3 x 1.0 mm² (127 x Ø 0.1 mm)		
Electrical connection - slot		
Connector: 8 x M12; coding: A; Moulded body: TPU; Contacts: gold-plated; Tightening torque: 0.5 Nm		
		

Splitter box

ZDO8H05HMSS0020B19

Connection



Core colours :

BK =	black
BN =	brown
BU =	blue
GN =	green
GY =	grey
PK =	pink
RD =	red
VT =	lilac
WH =	white
YE =	yellow

E12071

Splitter box

ZDO8H05HMSS0020B19

