


E12332



Connection cable

VDOGH040MSS0015C04STGH040MSS

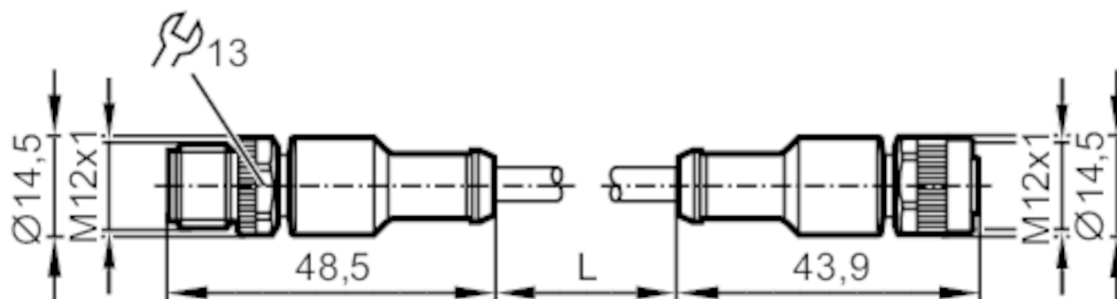

Application

Special feature	Free from silicone; Gold-plated contacts; Screened cable
Free from silicone	yes

Electrical data

Operating voltage	[V]	< 50 AC / < 60 DC
Protection class		III
Max. current load total	[A]	4

Operating conditions

Ambient temperature	[°C]	-25...85
Protection		IP 68

Mechanical data

Weight	[g]	612.5
Dimensions	[mm]	14.5 x 14.5 x 48.5
Materials		PUR
Moulded-body material		PUR
Material nut		diecast zinc, nickel-plated

Remarks

Pack quantity		1 pcs.
---------------	--	--------

Connection cable

VDOGH040MSS0015C04STGH040MSS

Electrical connection - plug


Connector: 1 x M12, straight; coding: A; Moulded body: PUR; Locking: diecast zinc, nickel-plated; Contacts: gold-plated; Tightening torque: 0.7...0.9 Nm



Electrical connection

Cable: 15 m, PUR, black, Ø 5 mm, shielded; 4 x 0.34 mm² (42 x Ø 0.1 mm)

Connection

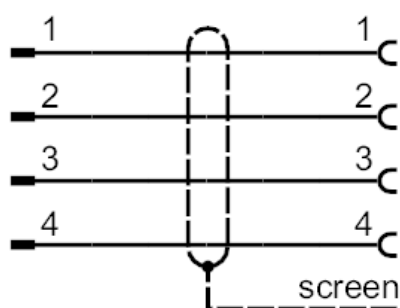

Electrical connection - socket

Connector: 1 x M12, straight; coding: A; Moulded body: PUR; Locking: diecast zinc, nickel-plated; Contacts: gold-plated; Tightening torque: 0.7...0.9 Nm

