

E33014




Process adapter hygienic pipe fitting

ADAPT IFM-DIN11851/DN65(2.5)

Article no longer available - archive entry

The alternative article requires the use of a new sensor with Aseptoflex Vario external thread

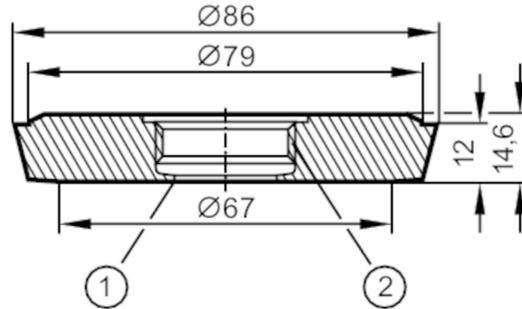

- 1 Aseptoflex thread
- 2 Aseptoflex sealing edge

EC 1935/2004 FCM FDA

Application

Pressure rating [bar] 25

Tests / approvals

Pressure Equipment Directive	A possible classification to PED depends on the application and has to be carried out by the user / operator.
Safety instructions	The compatibility between medium and product material has to be checked in all applications.

Mechanical data

Weight [g]	581
Materials	stainless steel (316L/1.4404)
Sensor connection	Aseptoflex
Process connection	hygienic pipe fitting DN65 (2,5") DIN 11851
Surface characteristics Ra/Rz of the wetted parts	0.4 / 4
Hygienic equipment class to DIN 11866	H4

Remarks

Pack quantity 1 pcs.