


E70143



Jumper cable with valve plug

VVDAB031--S00,3A03STAH030VAS

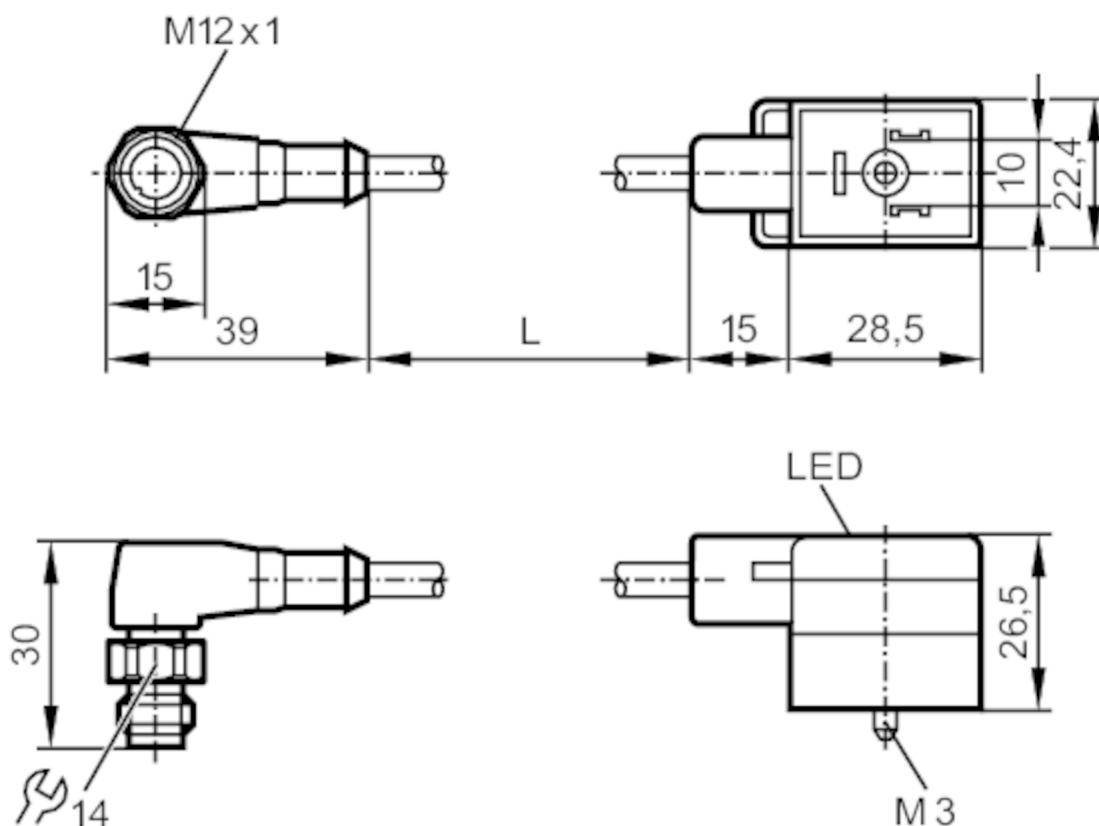

Application		
Special feature	Halogen-free	
Electrical data		
Operating voltage	[V]	< 24 AC/DC
Operating conditions		
Ambient temperature	[°C]	-25...90
Protection	IP 67	
Mechanical data		
Weight	[g]	58.7
Dimensions	[mm]	30 x 15 x 39
Materials	PUR	
Moulded-body material	PUR	
Material nut	stainless steel (316L/1.4404)	
Displays / operating elements		
Display	switching status	1 x LED, yellow
Accessories		
Items supplied	screw	
	panel for labelling	

E70143



Jumper cable with valve plug

VVDAB031--S00,3A03STAH030VAS

 
Remarks

Pack quantity

1 pcs.

Electrical connection - plug


Connector: 1 x M12, angled; coding: A; Moulded body: PUR; Locking: stainless steel (316L/1.4404)



Electrical connection

Cable: 0.3 m, PUR, Halogen-free, black, Ø 5.5 mm; 3 x 0.5 mm² (16 x Ø 0.2 mm)

Connection

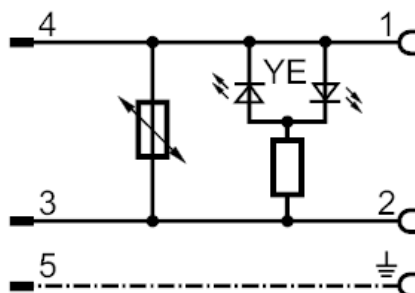

Electrical connection - socket

Connector: 1 x valve type B DIN, angled; Moulded body: PUR; Locking: stainless steel (316L/1.4404)

