


E79998



AS-Interface flat cable insulation displacement connector

FC connector, M12, V2A, 1m

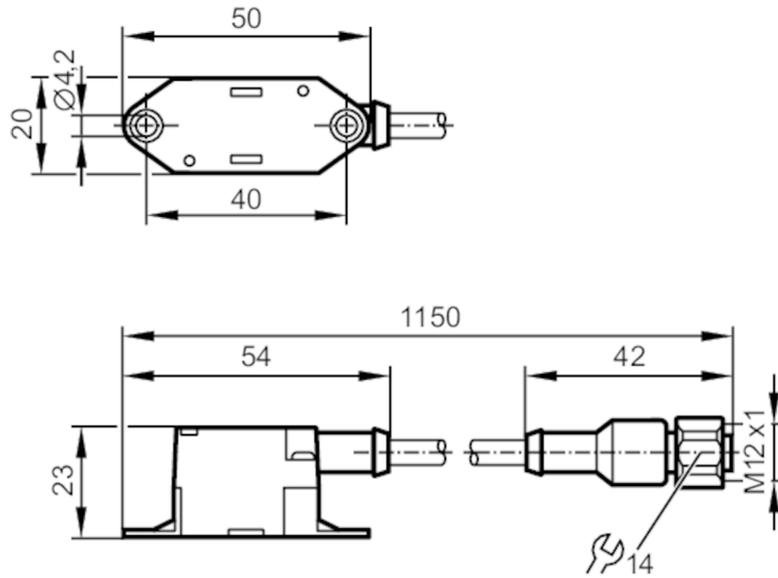

Application

Special feature	Gold-plated contacts
Design	AS-i

Electrical data

Operating voltage	[V]	26.5...31.6 DC
Max. current load total	[A]	2

Operating conditions

Ambient temperature	[°C]	-20...70
Protection		IP 67

Mechanical data

Weight	[g]	82.7
Materials		housing upper part: PUR; housing lower part: PA 6.6; screw: stainless steel (303/1.4305); Lock nut: stainless steel (303/1.4305)


Remarks

Remarks	The flat cable must not end in the splitter. Use a flat cable seal or heat-shrink cap for sealing.
Pack quantity	1 pcs.

Electrical connection

Cable: 1 m, PVC, Ø 5.75 mm; 2 x 0.75 mm², PVC

Connector: M12, straight; coding: A; Contacts: gold-plated

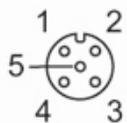


E79998



AS-Interface flat cable insulation displacement connector

FC connector, M12, V2A, 1m

Connection

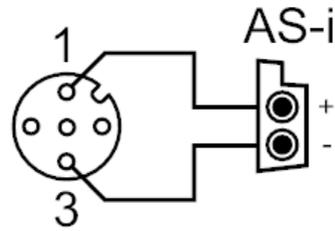

1	AS-i +
3	AS-i -