


# ZH4119



## Connecting cable with plug

ASTGH120MSS0010K12

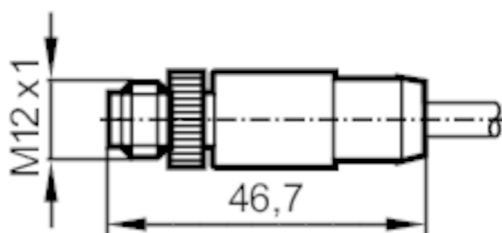

### Application

|                 |                                      |
|-----------------|--------------------------------------|
| Special feature | Gold-plated contacts; Screened cable |
|-----------------|--------------------------------------|

### Electrical data

|                         |     |            |
|-------------------------|-----|------------|
| Operating voltage       | [V] | < 30 AC/DC |
| Protection class        |     | II         |
| Max. current load total | [A] | 1.5        |

### Operating conditions

|                              |      |          |
|------------------------------|------|----------|
| Ambient temperature          | [°C] | -30...80 |
| Ambient temperature (moving) | [°C] | -5...80  |
| Protection                   |      | IP 67    |

### Mechanical data

|                       |      |                     |
|-----------------------|------|---------------------|
| Weight                | [g]  | 618.6               |
| Dimensions            | [mm] | 14.5 x 14.5 x 48.5  |
| Materials             |      | TPU                 |
| Moulded-body material |      | TPU                 |
| Material nut          |      | zinc, nickel-plated |

### Remarks

|               |        |
|---------------|--------|
| Pack quantity | 1 pcs. |
|---------------|--------|

# ZH4119



## Connecting cable with plug


ASTGH120MSS0010K12

### Electrical connection

Cable: 10 m, PUR, black, Ø 6.5 mm, shielded; 12 x 0.14 mm<sup>2</sup> (18 x Ø 0.1 mm )

### Electrical connection - plug

Connector: 1 x M12, straight; Moulded body: TPU; Locking: zinc, nickel-plated; Contacts: gold-plated; Tightening torque: 0.4 Nm

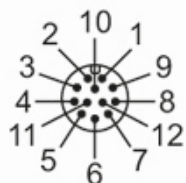

### Connection