


E10815



Connection cable

VDOGH040MSS00,2A03STGX030

Article no longer available - archive entry

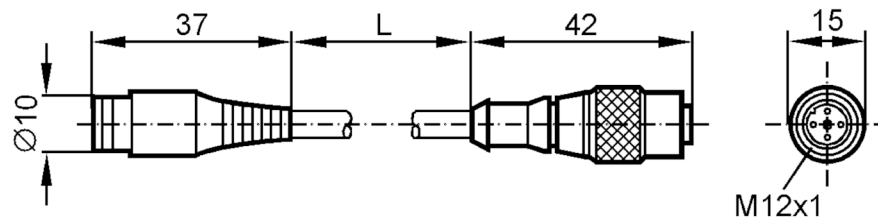

Electrical data

Operating voltage [V] 10...55 DC

Operating conditions

Ambient temperature [°C] -25...70

Protection IP 65

Mechanical data

Materials TPU

Material nut brass, nickel-plated / brass, nickel-plated

Remarks

Pack quantity 1 pcs.

Electrical connection - plug

Connector: 1 x Torson, straight; Moulded body: TPU; Locking: brass, nickel-plated



E10815




Connection cable

VDOGH040MSS00,2A03STGX030

Electrical connection


Cable: 0.2 m, PUR / PVC

Connection

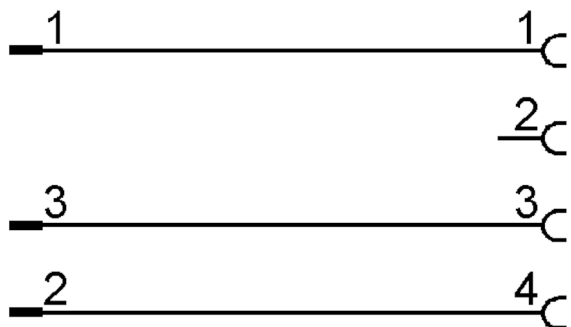

Electrical connection - socket

 Connector: 1 x M12, straight; Moulded body: TPU; Locking: brass, nickel-plated



Article no longer available - archive entry