


Fibre optic diffuse reflection sensor

FT-00-M-V-E1/2,5M

Article no longer available - archive entry

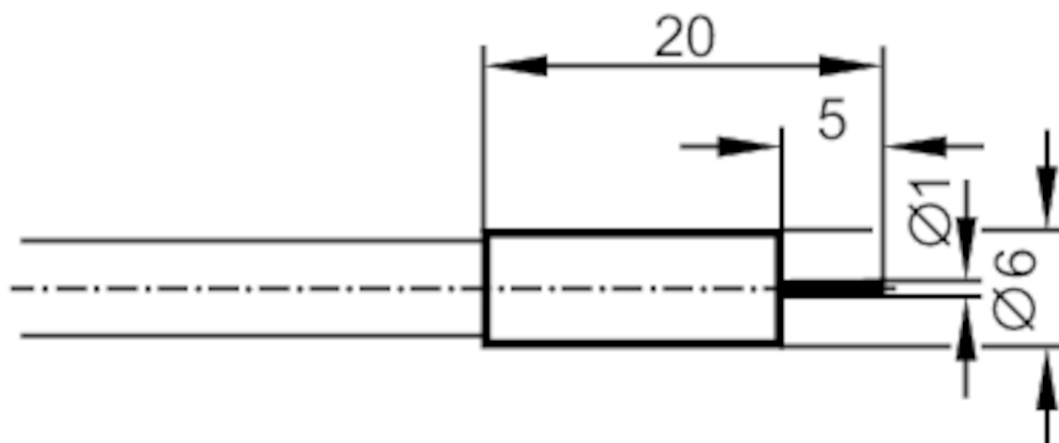

Application

Function principle

Diffuse reflection sensor

Detection zone

Range with fibre optic
amplifier type

OKF; OUF

OKF

Range fibre optics

[mm]

6

OUF

Range fibre optics

[mm]

6

Operating conditions

Ambient temperature

[°C]

-20...150

Mechanical data

Version of sensing head

straight

Sensing head diameter

[mm]

1

Sensing head length

[mm]

5

Total length

[mm]

2500

Min. bending radius

[mm]

20

Fibre material

glass

Fibre head material

stainless steel (1.4305 / 303)

E20698



Fibre optic diffuse reflection sensor

FT-00-M-V-E1/2,5M

Fibre sheath material	metal silicone
Remarks	
Pack quantity	1 pcs.