


E20323



Fibre optic diffuse reflection sensor

FT-30-A-A-R8/4m

discontinued article

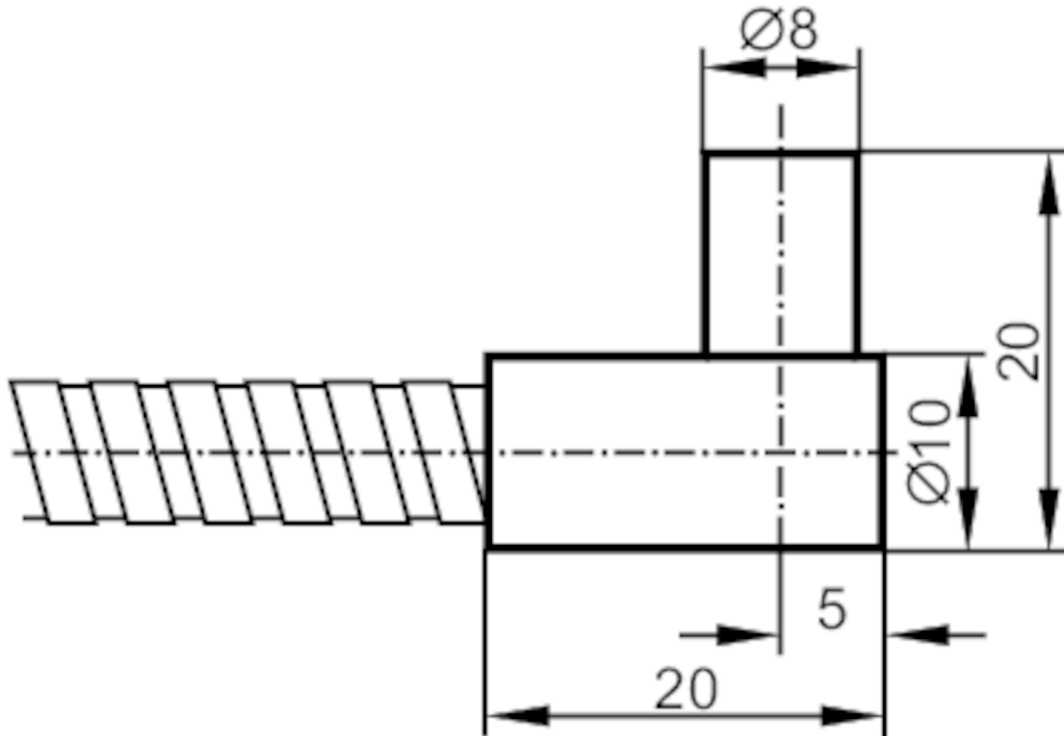

Application

Function principle Diffuse reflection sensor

Detection zone

Range with fibre optic amplifier type OIF

OIF

Range fibre optics [mm] 36

Operating conditions

Ambient temperature [°C] -40...290

Mechanical data

Version of sensing head angled

Total length [mm] 4000

Min. bending radius [mm] 30

Materials Adapter: PA

Fibre material glass

Fibre head material aluminium

Fibre sheath material aluminium

Remarks

Pack quantity 1 pcs.

E20323

Fibre optic diffuse reflection sensor

FT-30-A-A-R8/4m



discontinued article
