


ANT860



RFID UHF antenna

DTRUHF_AGRWKOTN04

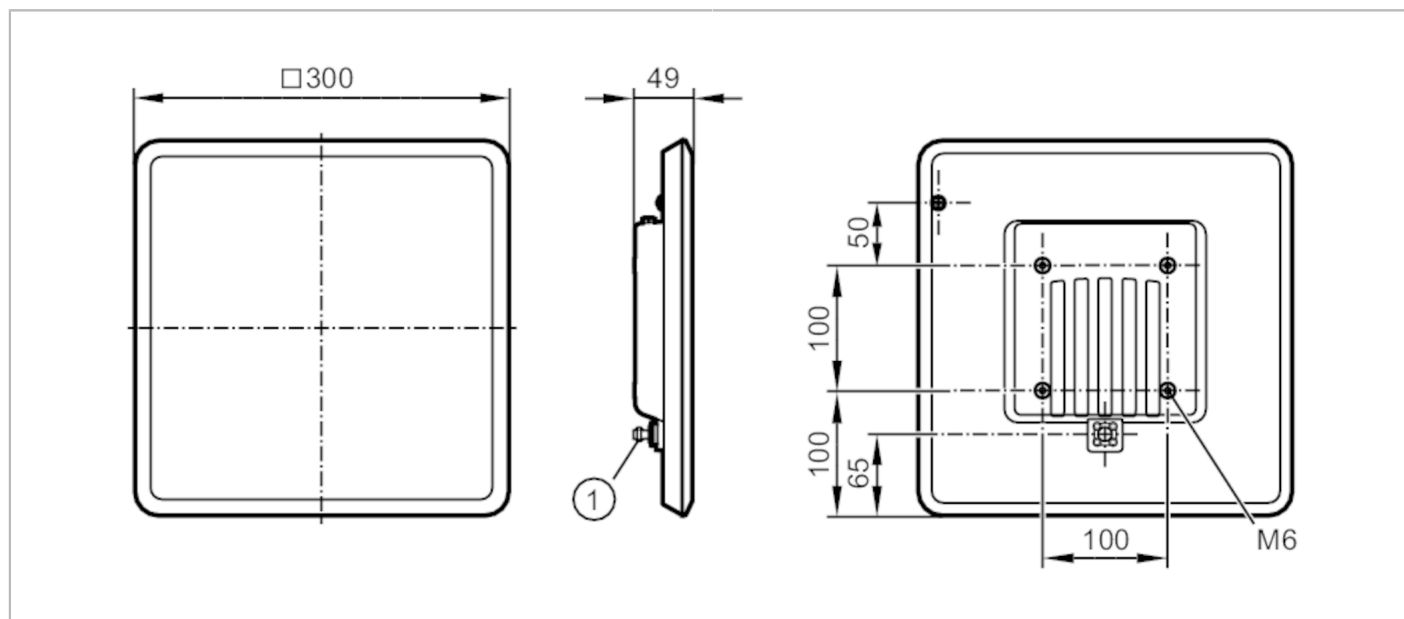

Electrical data

Operating frequency	[MHz]	865...868 (ETSI); (India: 865...867 MHz)
Antenna connections		1; (TNC socket)
Polarisation		circular
Transmission power ERP	[mW]	1995
Antenna gain	[dB]	8.5
Impedance	[Ω]	50

Detection zone

Angle of aperture	[°]	65
-------------------	-----	----

Operating conditions

Ambient temperature	[°C]	-40...70
Storage temperature	[°C]	-40...85
Protection		IP 67

Mechanical data

Weight	[g]	2395.5
Housing		rectangular
Dimensions	[mm]	300 x 300 x 79
Materials		housing: aluminium; TNC socket: brass / PTFE; Protective cover: plastics;

Remarks

Pack quantity		1 pcs.
---------------	--	--------